

# Flanged bronze nut



## BFM

## 2 start, right hand thread

- **Toleranced flange**
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze CuSn8P


### Accessoires

- LFM stainless steel leadscrew



Toleranced flange

2 Start

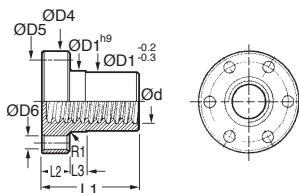

### DISCOUNTS

 
Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

Part number	Pitch			ØD1	ØD4	ØD5	ØD6	L1	L2	L3	Price each	
	Ød	P									1 to 9	20 to 39**
BFM126	12	6	28	48	38	6	35	12	8	50,83 €	30,50 €	
BFM168	16	8	28	48	38	6	35	12	8	51,00 €	30,60 €	
BFM188	18	8	28	48	38	6	35	12	8	51,00 €	30,60 €	
BFM208	20	8	32	55	45	7	44	12	8	69,76 €	41,86 €	
BFM2210	22	10	32	55	45	7	44	12	8	82,40 €	49,44 €	
BFM2410	24	10	32	55	45	7	44	12	8	67,98 €	40,79 €	
BFM2810	28	10	38	62	50	7	46	14	8	101,15 €	60,70 €	
BFM3012	30	12	38	62	50	7	46	14	8	90,89 €	54,54 €	
BFM3212	32	12	45	70	58	7	54	16	10	144,72 €	86,83 €	
BFM3612	36	12	45	70	58	7	54	16	10	144,44 €	86,67 €	
BFM4014	40	14	63	95	78	9	66	16	12	228,30 €	136,98 €	

Dimensions in mm

\*\* refer to discounts

## Our other products



PM3

Wormwheel ,  
Machined plastic  
(delrin)



 
PPOss

Pad eye on mounting  
plate oval, Stainless  
steel



HD

Double needle roller  
universal joint, Heavy  
duty



CAB

Galvanised steel  
cable, Galvanised  
steel



RHTplss

High Temperature  
Castor, up to 200kg



CFS

Miniature cam  
follower, Miniature



ACLAPA

Magnetic stop for  
aluminium profile,  
Magnetic stop



CAP880

Side flexing slim slat  
top chain acetal,  
Narrow range 880



BAG0

Locking rings in steel ,  
Steel



HLUT

Spoked handwheel  
with handle,  
Aluminium



RURp

Wheel pivoting with  
plate, Polyurethane -  
Aluminium rim (Free  
running)



MHXred

Reducing sleeve  
male/female,  
Hexagonal - stainless  
steel

## Complementary products



LFM2

Steel leadscrew,  
Medium carbon steel -  
2 threads



LRM2

Cylindrical bronze nut,  
Bronze - 2 threads



LFM2

Steel leadscrew,  
Medium carbon steel -  
2 threads



LFM2

Steel leadscrew,  
Medium carbon steel -  
2 threads