

# Flanged bronze nut



## BFM

## 2 start, right hand thread


- **Toleranced flange**
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze CuSn8P

### Accessoires

- LFM stainless steel leadscrew



**2 Start**

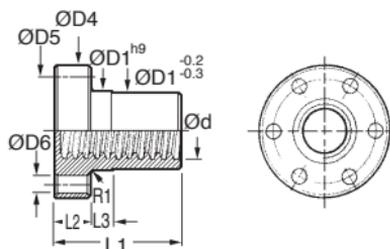

### DISCOUNTS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

Part number	Pitch			ØD1	ØD4	ØD5	ØD6	L1	L2	L3	Price each	
	Ød	P									1 to 9	20 to 39**
BFM126	12	6	28	48	38	6	35	12	8	50,83 €	30,50 €	
BFM168	16	8	28	48	38	6	35	12	8	51,00 €	30,60 €	
BFM188	18	8	28	48	38	6	35	12	8	51,00 €	30,60 €	
BFM208	20	8	32	55	45	7	44	12	8	69,76 €	41,86 €	
BFM2210	22	10	32	55	45	7	44	12	8	82,40 €	49,44 €	
BFM2410	24	10	32	55	45	7	44	12	8	67,98 €	40,79 €	
BFM2810	28	10	38	62	50	7	46	14	8	101,15 €	60,70 €	
BFM3012	30	12	38	62	50	7	46	14	8	90,89 €	54,54 €	
BFM3212	32	12	45	70	58	7	54	16	10	144,72 €	86,83 €	
BFM3612	36	12	45	70	58	7	54	16	10	144,44 €	86,67 €	
BFM4014	40	14	63	95	78	9	66	16	12	228,30 €	136,98 €	

Dimensions in mm

\*\* refer to discounts

## Our other products



PTA100ssEB  
Articulated foot with sheet metal base  
Ø100, 15000N



NKX  
Combined bearing without inner ring,  
Needle and ball bearings



PSG3  
Spur gear - precision range, Case hardened  
steel 20NCD2



PSG3  
Spur gear - precision range, Pre-hardened  
Steel 35NCD6



PP50  
Worm and wheel gear reducer, from 6.50 to  
12.80 Nm



RJ11\_27  
Sealing strip, Not clipping



UCP\_SS  
Stainless steel pillow block bearing,  
Stainless steel



PPRss  
Pad eye on mounting plate round, Stainless  
steel



FF15  
Offset spur gear reducer, from 2.20 to  
5.50 Nm



PW\_PWG25  
Worm - precision range, Stainless steel



VTLF  
3 lobed handle, Polyamide - Brass



CHA1056\_U4  
Screw-in hinge, Section 40X40

## Complementary products



LFM2  
Steel leadscrew, Medium carbon steel -  
2 threads



LRM2  
Cylindrical bronze nut, Bronze - 2 threads



LFM2  
Steel leadscrew, Medium carbon steel -  
2 threads



LFM2  
Steel leadscrew, Medium carbon steel -  
2 threads