

# Flanged bronze nut



## BFM

## 2 start, right hand thread

- **Toleranced flange**
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze CuSn8P


### Accessoires

- LFM stainless steel leadscrew



Toleranced flange

2 Start

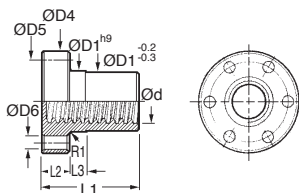

### DISCOUNTS

| Qty   | 1+   | 10+  | 20+  | 40+        |
|-------|------|------|------|------------|
| Disc. | List | -30% | -40% | On request |

| Part number | Pitch |    | ØD1 | ØD4 | ØD5 | ØD6 | L1 | L2 | L3 | Price each |            |
|-------------|-------|----|-----|-----|-----|-----|----|----|----|------------|------------|
|             | Ød    | P  |     |     |     |     |    |    |    | 1 to 9     | 20 to 39** |
| BFM126      | 12    | 6  | 28  | 48  | 38  | 6   | 35 | 12 | 8  | 50,83 €    | 30,50 €    |
| BFM168      | 16    | 8  | 28  | 48  | 38  | 6   | 35 | 12 | 8  | 51,00 €    | 30,60 €    |
| BFM188      | 18    | 8  | 28  | 48  | 38  | 6   | 35 | 12 | 8  | 51,00 €    | 30,60 €    |
| BFM208      | 20    | 8  | 32  | 55  | 45  | 7   | 44 | 12 | 8  | 69,76 €    | 41,86 €    |
| BFM2210     | 22    | 10 | 32  | 55  | 45  | 7   | 44 | 12 | 8  | 82,40 €    | 49,44 €    |
| BFM2410     | 24    | 10 | 32  | 55  | 45  | 7   | 44 | 12 | 8  | 67,98 €    | 40,79 €    |
| BFM2810     | 28    | 10 | 38  | 62  | 50  | 7   | 46 | 14 | 8  | 101,15 €   | 60,70 €    |
| BFM3012     | 30    | 12 | 38  | 62  | 50  | 7   | 46 | 14 | 8  | 90,89 €    | 54,54 €    |
| BFM3212     | 32    | 12 | 45  | 70  | 58  | 7   | 54 | 16 | 10 | 144,72 €   | 86,83 €    |
| BFM3612     | 36    | 12 | 45  | 70  | 58  | 7   | 54 | 16 | 10 | 144,44 €   | 86,67 €    |
| BFM4014     | 40    | 14 | 63  | 95  | 78  | 9   | 66 | 16 | 12 | 228,30 €   | 136,98 €   |

Dimensions in mm

\*\* refer to discounts

## Our other products



GE14

Toggle latches, With padlock-holder



RFKfp

Stainless steel gearbox - accessories, Mounting bracket



SSDB

Stainless steel bevel gear, 2:1



CHA138

Screwed hinge with threaded insert, 138 degrees



PCM

Fixed cylindrical handle, Fixed non-turning handle



RTE

Rotex®, jaw coupling, steel



CABPVC

PVC covered galvanized steel cable, Galvanised steel with



SSG1\_304L

Stainless steel spur gear, Stainless steel 304L



BTC20\_10

End cap for rectangular tube, Standard



 
PGMSS

Stainless steel pull handle, Stainless steel



NTM

Nylon tipped set screw, Nylon-point



Q3

Double row angular contact ball bearing, Angular contact - Steel

## Complementary products



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



LRM2

Cylindrical bronze nut, Bronze - 2 threads



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



LFM2

Steel leadscrew, Medium carbon steel - 2 threads