

Flanged bronze nut



BFM

2 start, right hand thread

- **Toleranced flange**
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze CuSn8P


Accessoires

- LFM stainless steel leadscrew



Toleranced flange

2 Start

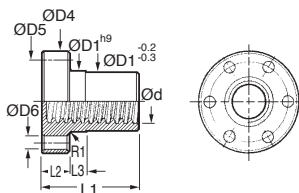

DISCOUNTS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

Part number	Pitch		ØD1	ØD4	ØD5	ØD6	L1	L2	L3	Price each	
	Ød	P								1 to 9	20 to 39**
BFM126	12	6	28	48	38	6	35	12	8	50,83 €	30,50 €
BFM168	16	8	28	48	38	6	35	12	8	51,00 €	30,60 €
BFM188	18	8	28	48	38	6	35	12	8	51,00 €	30,60 €
BFM208	20	8	32	55	45	7	44	12	8	69,76 €	41,86 €
BFM2210	22	10	32	55	45	7	44	12	8	82,40 €	49,44 €
BFM2410	24	10	32	55	45	7	44	12	8	67,98 €	40,79 €
BFM2810	28	10	38	62	50	7	46	14	8	101,15 €	60,70 €
BFM3012	30	12	38	62	50	7	46	14	8	90,89 €	54,54 €
BFM3212	32	12	45	70	58	7	54	16	10	144,72 €	86,83 €
BFM3612	36	12	45	70	58	7	54	16	10	144,44 €	86,67 €
BFM4014	40	14	63	95	78	9	66	16	12	228,30 €	136,98 €

Dimensions in mm

** refer to discounts

Our other products



TCXR

Automatic chain tensioner, With steel sprocket



INS

Self tapping steel insert, Steel



P55

Worm and wheel gear reducer, up to 57 Nm



RFLVcap

Stainless steel protective cover, Closed protective cover



PLC_PLT

Magnetic stud with central hole, With central hole



PSP

Support profile, Panel support



PTMR

Telescopic furniture foot, threaded stud



 
RTN

BoWex® curved tooth gear coupling, Nylon



BPM

Slotted spring plunger with ball tip, Steel



M0

Worm and wheel set, Machined plastic



PLA

Flat magnet, Flat magnet



GLT3E-50

Telescopic drawer,

Complementary products



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



LRM2

Cylindrical bronze nut, Bronze - 2 threads



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



LFM2

Steel leadscrew, Medium carbon steel - 2 threads