


Single housed bearing



BH01


With tight fitting bearing

- Housing with tight fitting bearing
- ZZ bearing (with shielding)
- Materials:
Housing: zinc plated steel (60C40), natural finish
Bearing: steel

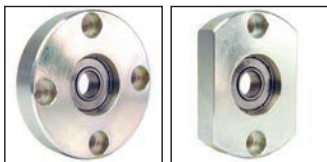


Options

- Flange with bearing retained by circlips (BH02)

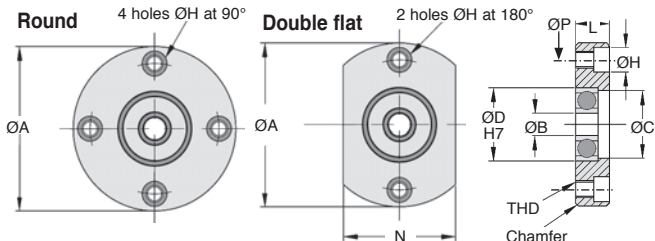

| Part number | | | ØB | ØD | ØC | L | ØA |
|----------------|----------------|----------------|----|------------|-------|----|----|
| Round | Double flat | Square | | | | | |
| BH0100-40-623 | BH0101-40-623 | BH0102-40-623 | 3 | Ø10x4Deep | Ø8,5 | 8 | 40 |
| BH0100-40-634 | BH0101-40-634 | BH0102-40-634 | 4 | Ø16x5Deep | Ø14,0 | 8 | 40 |
| BH0100-40-625 | BH0101-40-625 | BH0102-40-625 | 5 | Ø16x5Deep | Ø14,0 | 8 | 40 |
| BH0100-40-606 | BH0101-40-606 | BH0102-40-606 | 6 | Ø17x6Deep | Ø15,0 | 8 | 40 |
| BH0100-58-608 | BH0101-58-608 | BH0102-58-608 | 8 | Ø22x7Deep | Ø19,5 | 12 | 58 |
| BH0100-58-6000 | BH0101-58-6000 | BH0102-58-6000 | 10 | Ø26x8Deep | Ø24,0 | 12 | 58 |
| BH0100-58-6201 | BH0101-58-6201 | BH0102-58-6201 | 12 | Ø32x10Deep | Ø28,0 | 12 | 58 |
| BH0100-94-6202 | BH0101-94-6202 | BH0102-94-6202 | 15 | Ø35x11Deep | Ø33,0 | 18 | 94 |
| BH0100-94-6003 | BH0101-94-6003 | BH0102-94-6003 | 17 | Ø35x10Deep | Ø33,0 | 18 | 94 |
| BH0100-94-6004 | BH0101-94-6004 | BH0102-94-6004 | 20 | Ø42x12Deep | Ø38,0 | 18 | 94 |
| BH0100-94-6005 | BH0101-94-6005 | BH0102-94-6005 | 25 | Ø47x12Deep | Ø43,0 | 18 | 94 |
| BH0100-94-6006 | BH0101-94-6006 | BH0102-94-6006 | 30 | Ø55x13Deep | Ø50,0 | 18 | 94 |

Dimensions in mm

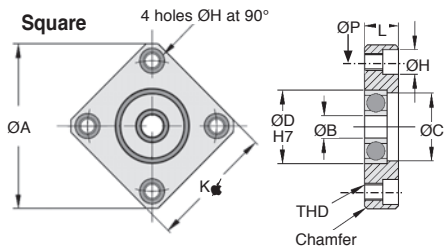

DISCOUNTS

| | | | | |
|-------|------|------|------|------------|
| Qty | 1+ | 6+ | 20+ | 40+ |
| Disc. | List | -15% | -20% | On request |

| ØP | ØH | THD | K | Bearing | N | Price each 1 to 5 | | |
|----|--------------------------|-------------|----|---------|----|-------------------|-------------|----------|
| | | | | | | Round | Double flat | Square |
| 30 | Ø7,5x4,5Deep (M4 Screw) | Ø4,20 (M5) | 30 | 623ZZ | 24 | 47,26 € | 53,47 € | 47,26 € |
| 30 | Ø7,5x4,5Deep (M4 Screw) | Ø4,20 (M5) | 30 | 634ZZ | 24 | 47,26 € | 53,47 € | 55,94 € |
| 30 | Ø7,5x4,5Deep (M4 Screw) | Ø4,20 (M5) | 30 | 625ZZ | 24 | 47,26 € | 53,47 € | 55,94 € |
| 30 | Ø7,5x4,5Deep (M4 Screw) | Ø4,20 (M5) | 30 | 606ZZ | 24 | 47,26 € | 53,47 € | 55,94 € |
| 46 | Ø9,5x5,5Deep (M5 Screw) | Ø5,20 (M6) | 44 | 608ZZ | 40 | 78,40 € | 66,34 € | 70,01 € |
| 46 | Ø9,5x5,5Deep (M5 Screw) | Ø5,20 (M6) | 44 | 6000ZZ | 40 | 78,40 € | 66,34 € | 70,01 € |
| 46 | Ø9,5x5,5Deep (M5 Screw) | Ø5,20 (M6) | 44 | 6201ZZ | 40 | 78,40 € | 66,34 € | 70,01 € |
| 78 | Ø15,0x8,5Deep (M8 Screw) | Ø8,50 (M10) | 77 | 6202ZZ | 67 | 124,36 € | 140,45 € | 149,39 € |
| 78 | Ø15,0x8,5Deep (M8 Screw) | Ø8,50 (M10) | 77 | 6003ZZ | 67 | 124,36 € | 140,45 € | 149,39 € |
| 78 | Ø15,0x8,5Deep (M8 Screw) | Ø8,50 (M10) | 77 | 6004ZZ | 67 | 124,36 € | 140,45 € | 149,39 € |
| 78 | Ø15,0x8,5Deep (M8 Screw) | Ø8,50 (M10) | 77 | 6005ZZ | 67 | 124,36 € | 140,45 € | 149,39 € |
| 78 | Ø15,0x8,5Deep (M8 Screw) | Ø8,50 (M10) | 77 | 6006ZZ | 67 | 124,36 € | 140,45 € | 149,39 € |

Dimensions in mm

Our other products



RTL450
Self-centering locking assembly, High torque



TIFss
Threaded stud -
DIN976A, Stainless
steel



MEP
Revolving handle for
handwheel, Fixed




DOMI30
Connecting kits, XZ
linking kit



RAM30
Manual bevel
gearbox, Bevel



 NCT
Square tube
connector, Fixed
angle



EZY
Cylindrical stop, Steel



KBS_UU
Stainless steel closed
precision linear
bearing, Precision -
stainle...



FF20
Offset spur gear
reducer, from 5.80 to
23 Nm



NDS14C
Angular connector,
Universal angular
connector



CHAC4040NP
Square hinge with
riveted pin, not
drilled, Square with



RT25ss
Self-centering flanged
locking assembly,
Medium/high torque

Complementary products



BH01
Single housed
bearing, Bearing fitted
with adhesive



BH01
Single housed
bearing, Bearing fitted
with adhesive