


Single housed bearing



BH01


With tight fitting bearing

- Housing with tight fitting bearing
- ZZ bearing (with shielding)
- Materials:
Housing: zinc plated steel (60C40), natural finish
Bearing: steel

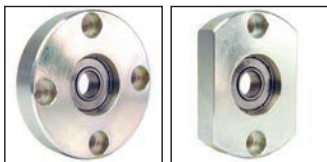


Options

- Flange with bearing retained by circlips (BH02)

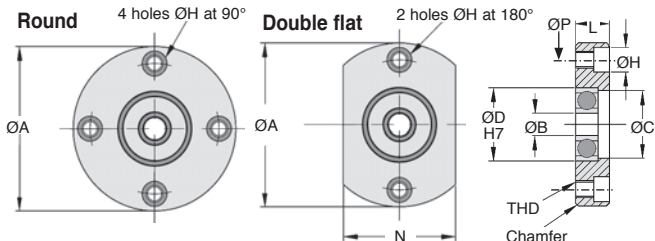

Part number			ØB	ØD	ØC	L	ØA
Round	Double flat	Square					
BH0100-40-623	BH0101-40-623	BH0102-40-623	3	Ø10x4Deep	Ø8,5	8	40
BH0100-40-634	BH0101-40-634	BH0102-40-634	4	Ø16x5Deep	Ø14,0	8	40
BH0100-40-625	BH0101-40-625	BH0102-40-625	5	Ø16x5Deep	Ø14,0	8	40
BH0100-40-606	BH0101-40-606	BH0102-40-606	6	Ø17x6Deep	Ø15,0	8	40
BH0100-58-608	BH0101-58-608	BH0102-58-608	8	Ø22x7Deep	Ø19,5	12	58
BH0100-58-6000	BH0101-58-6000	BH0102-58-6000	10	Ø26x8Deep	Ø24,0	12	58
BH0100-58-6201	BH0101-58-6201	BH0102-58-6201	12	Ø32x10Deep	Ø28,0	12	58
BH0100-94-6202	BH0101-94-6202	BH0102-94-6202	15	Ø35x11Deep	Ø33,0	18	94
BH0100-94-6003	BH0101-94-6003	BH0102-94-6003	17	Ø35x10Deep	Ø33,0	18	94
BH0100-94-6004	BH0101-94-6004	BH0102-94-6004	20	Ø42x12Deep	Ø38,0	18	94
BH0100-94-6005	BH0101-94-6005	BH0102-94-6005	25	Ø47x12Deep	Ø43,0	18	94
BH0100-94-6006	BH0101-94-6006	BH0102-94-6006	30	Ø55x13Deep	Ø50,0	18	94

Dimensions in mm

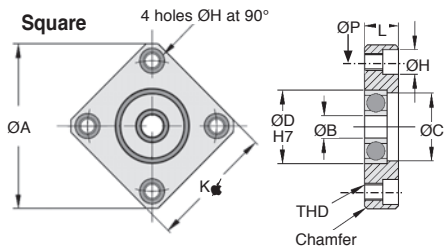

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

ØP	ØH	THD	K	Bearing	N	Price each 1 to 5		
						Round	Double flat	Square
30	Ø7,5x4,5Deep (M4 Screw)	Ø4,20 (M5)	30	623ZZ	24	47,26 €	53,47 €	47,26 €
30	Ø7,5x4,5Deep (M4 Screw)	Ø4,20 (M5)	30	634ZZ	24	47,26 €	53,47 €	55,94 €
30	Ø7,5x4,5Deep (M4 Screw)	Ø4,20 (M5)	30	625ZZ	24	47,26 €	53,47 €	55,94 €
30	Ø7,5x4,5Deep (M4 Screw)	Ø4,20 (M5)	30	606ZZ	24	47,26 €	53,47 €	55,94 €
46	Ø9,5x5,5Deep (M5 Screw)	Ø5,20 (M6)	44	608ZZ	40	78,40 €	66,34 €	70,01 €
46	Ø9,5x5,5Deep (M5 Screw)	Ø5,20 (M6)	44	6000ZZ	40	78,40 €	66,34 €	70,01 €
46	Ø9,5x5,5Deep (M5 Screw)	Ø5,20 (M6)	44	6201ZZ	40	78,40 €	66,34 €	70,01 €
78	Ø15,0x8,5Deep (M8 Screw)	Ø8,50 (M10)	77	6202ZZ	67	124,36 €	140,45 €	149,39 €
78	Ø15,0x8,5Deep (M8 Screw)	Ø8,50 (M10)	77	6003ZZ	67	124,36 €	140,45 €	149,39 €
78	Ø15,0x8,5Deep (M8 Screw)	Ø8,50 (M10)	77	6004ZZ	67	124,36 €	140,45 €	149,39 €
78	Ø15,0x8,5Deep (M8 Screw)	Ø8,50 (M10)	77	6005ZZ	67	124,36 €	140,45 €	149,39 €
78	Ø15,0x8,5Deep (M8 Screw)	Ø8,50 (M10)	77	6006ZZ	67	124,36 €	140,45 €	149,39 €

Dimensions in mm

Our other products




NSP

Right angled support clamp, Right angled support clamp



ACLERP

Roller block for aluminium profile, Without guide rail

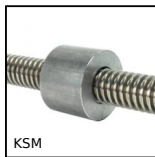

KSM

Cylindrical steel nut, Steel - 1 thread



 
PRES7HR

Manual workbench press, Force up to 700kg



PENC

Recessed handle, clip-in




CXS

External circlip DIN471, external DIN 471



YG1

 HEAVY DUTY spur gear, Steel 35NCD6



P20

Worm and wheel gear reducer, up to 5 Nm



RJA11_27

Sealing strip, Not clipping



DTR

Chain idler sprocket, Chain idler sprocket -



SDG

Adjustable guide support bracket,



PW_PWG15

Wheel - precision range, Bronze

Complementary products



BH01

Single housed bearing, Bearing fitted with adhesive



BH01

Single housed bearing, Bearing fitted with adhesive