


Single housed bearing



BH01


With tight fitting bearing

- Housing with tight fitting bearing
- ZZ bearing (with shielding)
- Materials:
Housing: zinc plated steel (60C40), natural finish
Bearing: steel

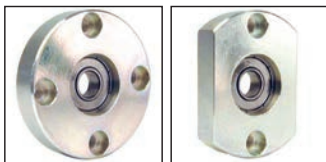


Options

- Flange with bearing retained by circlips (BH02)

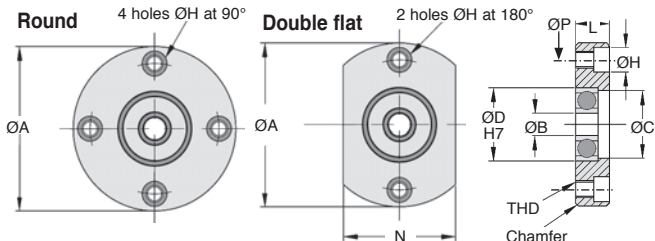

Part number			ØB	ØD	ØC	L	ØA
Round	Double flat	Square					
BH0100-40-623	BH0101-40-623	BH0102-40-623	3	Ø10x4Deep	Ø8,5	8	40
BH0100-40-634	BH0101-40-634	BH0102-40-634	4	Ø16x5Deep	Ø14,0	8	40
BH0100-40-625	BH0101-40-625	BH0102-40-625	5	Ø16x5Deep	Ø14,0	8	40
BH0100-40-606	BH0101-40-606	BH0102-40-606	6	Ø17x6Deep	Ø15,0	8	40
BH0100-58-608	BH0101-58-608	BH0102-58-608	8	Ø22x7Deep	Ø19,5	12	58
BH0100-58-6000	BH0101-58-6000	BH0102-58-6000	10	Ø26x8Deep	Ø24,0	12	58
BH0100-58-6201	BH0101-58-6201	BH0102-58-6201	12	Ø32x10Deep	Ø28,0	12	58
BH0100-94-6202	BH0101-94-6202	BH0102-94-6202	15	Ø35x11Deep	Ø33,0	18	94
BH0100-94-6003	BH0101-94-6003	BH0102-94-6003	17	Ø35x10Deep	Ø33,0	18	94
BH0100-94-6004	BH0101-94-6004	BH0102-94-6004	20	Ø42x12Deep	Ø38,0	18	94
BH0100-94-6005	BH0101-94-6005	BH0102-94-6005	25	Ø47x12Deep	Ø43,0	18	94
BH0100-94-6006	BH0101-94-6006	BH0102-94-6006	30	Ø55x13Deep	Ø50,0	18	94

Dimensions in mm

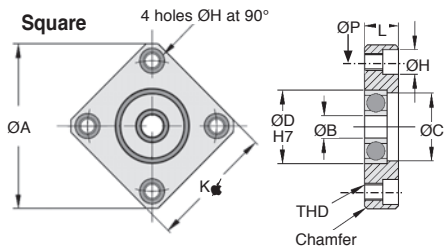

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

ØP	ØH	THD	K	Bearing	N	Price each 1 to 5		
						Round	Double flat	Square
30	Ø7,5x4,5Deep (M4 Screw)	Ø4,20 (M5)	30	623ZZ	24	47,26 €	53,47 €	47,26 €
30	Ø7,5x4,5Deep (M4 Screw)	Ø4,20 (M5)	30	634ZZ	24	47,26 €	53,47 €	55,94 €
30	Ø7,5x4,5Deep (M4 Screw)	Ø4,20 (M5)	30	625ZZ	24	47,26 €	53,47 €	55,94 €
30	Ø7,5x4,5Deep (M4 Screw)	Ø4,20 (M5)	30	606ZZ	24	47,26 €	53,47 €	55,94 €
46	Ø9,5x5,5Deep (M5 Screw)	Ø5,20 (M6)	44	608ZZ	40	78,40 €	66,34 €	70,01 €
46	Ø9,5x5,5Deep (M5 Screw)	Ø5,20 (M6)	44	6000ZZ	40	78,40 €	66,34 €	70,01 €
46	Ø9,5x5,5Deep (M5 Screw)	Ø5,20 (M6)	44	6201ZZ	40	78,40 €	66,34 €	70,01 €
78	Ø15,0x8,5Deep (M8 Screw)	Ø8,50 (M10)	77	6202ZZ	67	124,36 €	140,45 €	149,39 €
78	Ø15,0x8,5Deep (M8 Screw)	Ø8,50 (M10)	77	6003ZZ	67	124,36 €	140,45 €	149,39 €
78	Ø15,0x8,5Deep (M8 Screw)	Ø8,50 (M10)	77	6004ZZ	67	124,36 €	140,45 €	149,39 €
78	Ø15,0x8,5Deep (M8 Screw)	Ø8,50 (M10)	77	6005ZZ	67	124,36 €	140,45 €	149,39 €
78	Ø15,0x8,5Deep (M8 Screw)	Ø8,50 (M10)	77	6006ZZ	67	124,36 €	140,45 €	149,39 €


Dimensions in mm

Our other products



CHT63

 Asynchronous AC motor 0.12 to 0.22kW, 0.12 to 0.22kW



BLHM50

Right angled gearbox, double output shafts, up to 30 Nm



BZY

Cylindrical elasto mount, Steel



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



BPH

Ball transfer unit plain fit, High



CHALss

Piano hinge, Stainless steel



VTLB

Three-lobed knob, Thermoplastic / Brass or stainless steel insert



QNUP

Single row cylindrical roller bearing, 1 fixed inner flange and 1 fr...



CF

Cam follower, Standard - steel



GP

Spring loaded toggle latch, With padlock-holder



DOMI80

Accessories, Turntable



KB_OP

Open precision linear bearing, Precision - steel

Complementary products



BH01

Single housed bearing, Bearing fitted with adhesive



BH01

Single housed bearing, Bearing fitted with adhesive