


Single housed bearing assembly


BH02 Bearing retained by with circlips

- **Bearing mounted in housing with circlips**
- Housing supplied with bearing
- ZZ bearing (with shielding)
- **Materials:**
Housing: zinc plated steel (60C40), natural finish
Bearing: steel
Circlips: steel

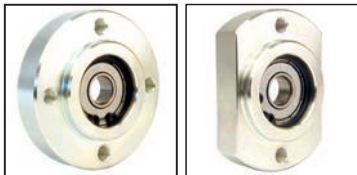


Options

- Flange with bearing glued in (BH01)

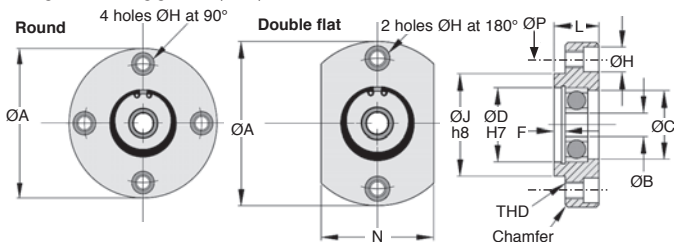

Part number			ØB	ØD	ØC	L	ØA	ØP
Round	Double flat	Square						
BH0200-40-623	BH0201-40-623	BH0202-40-623	3	Ø10x7Deep	Ø8,5	11	40	30
BH0200-40-634	BH0201-40-634	BH0202-40-634	4	Ø16x8Deep	Ø14,0	11	40	30
BH0200-40-625	BH0201-40-625	BH0202-40-625	5	Ø16x8Deep	Ø14,0	11	40	30
BH0200-40-606	BH0201-40-606	BH0202-40-606	6	Ø17x9Deep	Ø15,0	11	40	30
BH0200-58-608	BH0201-58-608	BH0202-58-608	8	Ø22x11Deep	Ø19,5	16	58	46
BH0200-58-6000	BH0201-58-6000	BH0202-58-6000	10	Ø26x12Deep	Ø24,0	16	58	46
BH0200-58-6201	BH0201-58-6201	BH0202-58-6201	12	Ø32x14Deep	Ø28,0	16	58	46
BH0200-94-6202	BH0201-94-6202	BH0202-94-6202	15	Ø35x18Deep	Ø33,0	25	94	78
BH0200-94-6003	BH0201-94-6003	BH0202-94-6003	17	Ø35x17Deep	Ø33,0	25	94	78
BH0200-94-6004	BH0201-94-6004	BH0202-94-6004	20	Ø42x19Deep	Ø38,0	25	94	78
BH0200-94-6005	BH0201-94-6005	BH0202-94-6005	25	Ø47x19Deep	Ø43,0	25	94	78
BH0200-94-6006	BH0201-94-6006	BH0202-94-6006	30	Ø55x20Deep	Ø50,0	25	94	78

Dimensions in mm

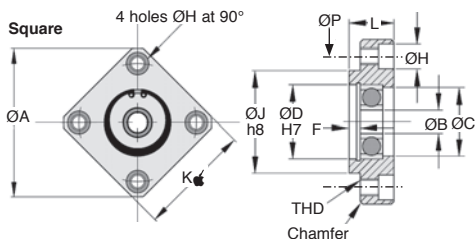

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Price each 1 to 5									
ØH	THD	K	Bearing	N	ØJ	F	Round	Double flat	Square
Ø7,5x4,5Deep. (M4 Screw)	Ø4,20 (M5)	30	623ZZ	24	Ø22x3	3	51,57 €	58,31 €	61,09 €
Ø7,5x4,5Deep. (M4 Screw)	Ø4,20 (M5)	30	634ZZ	24	Ø22x3	3	51,57 €	58,31 €	61,09 €
Ø7,5x4,5Deep. (M4 Screw)	Ø4,20 (M5)	30	625ZZ	24	Ø22x3	3	51,57 €	58,31 €	61,09 €
Ø7,5x4,5Deep. (M4 Screw)	Ø4,20 (M5)	30	606ZZ	24	Ø22x3	3	51,57 €	58,31 €	61,09 €
Ø9,5x5,5Deep. (M5 Screw)	Ø5,20 (M6)	44	608ZZ	40	Ø36x4	4	70,16 €	72,36 €	101,82 €
Ø9,5x5,5Deep. (M5 Screw)	Ø5,20 (M6)	44	6000ZZ	40	Ø36x4	4	70,16 €	72,36 €	101,82 €
Ø15,0x8,5Deep. (M8 Screw)	Ø5,20 (M6)	44	6201ZZ	40	Ø36x4	4	70,16 €	72,36 €	101,82 €
Ø15,0x8,5Deep. (M8 Screw)	Ø8,50 (M10)	77	6202ZZ	67	Ø66x6	7	101,77 €	114,85 €	163,01 €
Ø15,0x8,5Deep. (M8 Screw)	Ø8,50 (M10)	77	6003ZZ	67	Ø66x6	7	101,77 €	114,85 €	163,01 €
Ø15,0x8,5Deep. (M8 Screw)	Ø8,50 (M10)	77	6004ZZ	67	Ø66x6	7	101,74 €	114,85 €	163,01 €
Ø15,0x8,5Deep. (M8 Screw)	Ø8,50 (M10)	77	6005ZZ	67	Ø66x6	7	101,77 €	114,85 €	163,01 €
Ø15,0x8,5Deep. (M8 Screw)	Ø8,50 (M10)	77	6006ZZ	67	Ø66x6	7	101,77 €	114,85 €	163,01 €

 
Dimensions in mm

Our other products



BOX-TOR-ORFS

Box set of Nitrile O-rings NBR90Sh A, 7.65 x 1.78mm to 37.82 x 1.78



TBV

Manual lifting tables, 7kg



PCS_PA6

Plastic sprocket, 12.7mm (DIN 08B-1)



P55

Worm and wheel gear reducer, up to 57 Nm



PRF_ER

Joining bar for aluminium profile, joint bar



BLHT30

Right angled gearbox, from 1.65 to 4.40 Nm



MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



M2

Worm and wheel set, Unhardened steel



CLSCLP

Clevis components, short version, Steel -



HAS

Captive C washer, Slotted flat headed



YG1

HEAVY DUTY spur gear, Steel 35NCD6



EFTC

Fixing support, Stainless steel

Complementary products



BH02

Single housed bearing assembly, Bearing secured with circlips



BH02

Single housed bearing assembly, Bearing secured with circlips