


# Socket head button screw **ISO 7380** **Stal** **ISO**

## BHC

## Stainless steel A2

- **Conforms to ISO 7380**
- **Material:**  
stainless steel 302/304-A2
- Hexagonal socket
- Sold by the packet

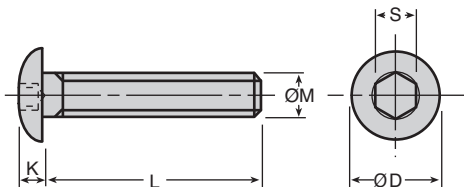

### DISCOUNTS

|            |      |      |            |
|------------|------|------|------------|
| N° packets | 1+   | 2+   | 4+         |
| Discounts  | List | -20% | On request |

| Part number  | Thread<br>ØM | Pitch | Length<br>L | ØD   | K    | S   | Qty. per<br>packet | Stock* | Price per<br>packet |
|--------------|--------------|-------|-------------|------|------|-----|--------------------|--------|---------------------|
| BHC4-8/SS/B  | M4           | 0,70  | 8           | 7,6  | 2,20 | 2,5 | 500                | ✓      | 12,03 €             |
| BHC4-10/SS/B | M4           | 0,70  | 10          | 7,6  | 2,20 | 2,5 | 500                | ✓      | 12,38 €             |
| BHC4-12/SS/B | M4           | 0,70  | 12          | 7,6  | 2,20 | 2,5 | 500                | ✓      | 19,25 €             |
| BHC4-16/SS/B | M4           | 0,70  | 16          | 7,6  | 2,20 | 2,5 | 500                | -      | 20,28 €             |
| BHC5-10/SS/B | M5           | 0,80  | 10          | 9,5  | 2,75 | 3,0 | 500                | ✓      | 21,66 €             |
| BHC5-12/SS/B | M5           | 0,80  | 12          | 9,5  | 2,75 | 3,0 | 500                | ✓      | 30,09 €             |
| BHC5-16/SS/B | M5           | 0,80  | 16          | 9,5  | 2,75 | 3,0 | 500                | -      | 32,84 €             |
| BHC5-20/SS/B | M5           | 0,80  | 20          | 9,5  | 2,75 | 3,0 | 500                | ✓      | 35,93 €             |
| BHC6-12/SS/B | M6           | 1,00  | 12          | 10,5 | 3,30 | 4,0 | 500                | ✓      | 33,36 €             |
| BHC6-16/SS/B | M6           | 1,00  | 16          | 10,5 | 3,30 | 4,0 | 500                | -      | 39,90 €             |
| BHC6-20/SS/B | M6           | 1,00  | 20          | 10,5 | 3,30 | 4,0 | 500                | ✓      | 46,25 €             |
| BHC6-25/SS/B | M6           | 1,00  | 25          | 10,5 | 3,30 | 4,0 | 500                | -      | 43,68 €             |
| BHC8-16/SS/B | M8           | 1,25  | 16          | 14,0 | 4,40 | 5,0 | 200                | ✓      | 30,40 €             |
| BHC8-20/SS/B | M8           | 1,25  | 20          | 14,0 | 4,40 | 5,0 | 200                | ✓      | 34,39 €             |
| BHC8-25/SS/B | M8           | 1,25  | 25          | 14,0 | 4,40 | 5,0 | 200                | -      | 38,03 €             |
| BHC8-30/SS/B | M8           | 1,25  | 30          | 14,0 | 4,40 | 5,0 | 200                | -      | 34,87 €             |

Dimensions in mm


## Our other products



PRES5HR  
Manual workbench press, Force up to 500kg



 CHINV2  
Invisible hinge, Invisible - Opening up to 125°



RPP8  
RPP heavy duty timing belt, RPP8



CDC  
Conical compression spring, Conical



HW\_HT  
Half-rail guide, Wheel



IBJss  
Ball and socket joint, Stainless steel



MDB\_MTB  
Moulded plastic bevel gear (nylon), 2:1




PT821  
Drive sprocket for slat top chain, Ranges 821 and 805




RBS  
Dynamic washer DIN2093, Steel



 PSPE20  
Conical flexible shaft handle Ø20, Black



 CHB  
Worm and wheel gear reducer, up to 22 Nm



BLHM70  
Right angled gearbox, up to 128 Nm


## Complementary products



 SHN  
Hexagonal nut DIN934, A2 Stainless steel



ACL-PR  
Joining plate for aluminium profile, Right angled connection



ACL-PR  
Joining plate for aluminium profile, Right angled connection



ACL-PLAngle  
Joining plate for aluminium profile, Angle connection