


Socket head button screw **ISO 7380** **Stal** **ISO**

BHC

Stainless steel A2

- **Conforms to ISO 7380**
- **Material:**
stainless steel 302/304-A2
- **Hexagonal socket**
- **Sold by the packet**

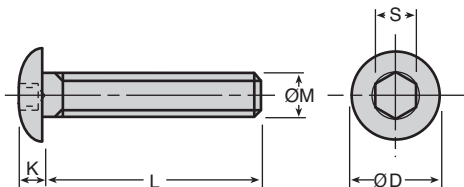

DISCOUNTS

N° packets	1+	2+	4+
Discounts	List	-20%	On request

Part number	Thread ØM	Pitch	Length L	ØD	K	S	Qty. per packet	Stock*	Price per packet
BHC4-8/SS/B	M4	0,70	8	7,6	2,20	2,5	500	✓	12,03 €
BHC4-10/SS/B	M4	0,70	10	7,6	2,20	2,5	500	✓	12,38 €
BHC4-12/SS/B	M4	0,70	12	7,6	2,20	2,5	500	✓	19,25 €
BHC4-16/SS/B	M4	0,70	16	7,6	2,20	2,5	500	-	20,28 €
BHC5-10/SS/B	M5	0,80	10	9,5	2,75	3,0	500	✓	21,66 €
BHC5-12/SS/B	M5	0,80	12	9,5	2,75	3,0	500	✓	30,09 €
BHC5-16/SS/B	M5	0,80	16	9,5	2,75	3,0	500	-	32,84 €
BHC5-20/SS/B	M5	0,80	20	9,5	2,75	3,0	500	✓	35,93 €
BHC6-12/SS/B	M6	1,00	12	10,5	3,30	4,0	500	✓	33,36 €
BHC6-16/SS/B	M6	1,00	16	10,5	3,30	4,0	500	-	39,90 €
BHC6-20/SS/B	M6	1,00	20	10,5	3,30	4,0	500	✓	46,25 €
BHC6-25/SS/B	M6	1,00	25	10,5	3,30	4,0	500	-	43,68 €
BHC8-16/SS/B	M8	1,25	16	14,0	4,40	5,0	200	✓	30,40 €
BHC8-20/SS/B	M8	1,25	20	14,0	4,40	5,0	200	✓	34,39 €
BHC8-25/SS/B	M8	1,25	25	14,0	4,40	5,0	200	-	38,03 €
BHC8-30/SS/B	M8	1,25	30	14,0	4,40	5,0	200	-	34,87 €


Dimensions in mm

Our other products



MFBC

Flexible Bellows coupling, Aluminium and Bronze - with clamping jaw

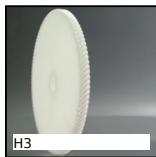

H3

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



SMS

Spiral bevel gear, 1:1



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Micromet...



 
LQT

Mechanical catch, Quick closing catch



SDA

Locking bolt support bracket, Mounting holes parallel to locating bolt



AWMP

Aluminium shaft for linear guide, Aluminium



 
VTH

Hexagonal headed bolts, Steel class 8.8




FAD

Threaded swivel feet, Swivel feet without



PITAss

 Locking bolt, with T handle



IN1

Internal gear, Machined plastic



PGMT

Pull handle, Steel

Complementary products



 
SHN

Hexagonal nut DIN934, A2 Stainless steel



ACL-PR

Joining plate for aluminium profile, Right angled connection



ACL-PR

Joining plate for aluminium profile, Right angled connection



ACL-PLAngle

Joining plate for aluminium profile, Angle connection