


Socket head button screw **ISO 7380** **Stal** **ISO**

BHC

Stainless steel A2

- **Conforms to ISO 7380**
- **Material:**
stainless steel 302/304-A2
- **Hexagonal socket**
- **Sold by the packet**

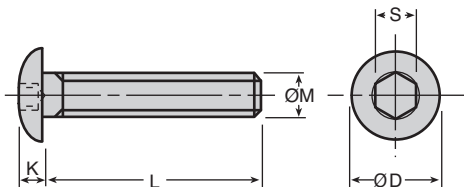

DISCOUNTS

N° packets	1+	2+	4+
Discounts	List	-20%	On request

Part number	Thread ØM	Pitch	Length L	ØD	K	S	Qty. per packet	Stock*	Price per packet
BHC4-8/SS/B	M4	0,70	8	7,6	2,20	2,5	500	✓	12,03 €
BHC4-10/SS/B	M4	0,70	10	7,6	2,20	2,5	500	✓	12,38 €
BHC4-12/SS/B	M4	0,70	12	7,6	2,20	2,5	500	✓	19,25 €
BHC4-16/SS/B	M4	0,70	16	7,6	2,20	2,5	500	-	20,28 €
BHC5-10/SS/B	M5	0,80	10	9,5	2,75	3,0	500	✓	21,66 €
BHC5-12/SS/B	M5	0,80	12	9,5	2,75	3,0	500	✓	30,09 €
BHC5-16/SS/B	M5	0,80	16	9,5	2,75	3,0	500	-	32,84 €
BHC5-20/SS/B	M5	0,80	20	9,5	2,75	3,0	500	✓	35,93 €
BHC6-12/SS/B	M6	1,00	12	10,5	3,30	4,0	500	✓	33,36 €
BHC6-16/SS/B	M6	1,00	16	10,5	3,30	4,0	500	-	39,90 €
BHC6-20/SS/B	M6	1,00	20	10,5	3,30	4,0	500	✓	46,25 €
BHC6-25/SS/B	M6	1,00	25	10,5	3,30	4,0	500	-	43,68 €
BHC8-16/SS/B	M8	1,25	16	14,0	4,40	5,0	200	✓	30,40 €
BHC8-20/SS/B	M8	1,25	20	14,0	4,40	5,0	200	✓	34,39 €
BHC8-25/SS/B	M8	1,25	25	14,0	4,40	5,0	200	-	38,03 €
BHC8-30/SS/B	M8	1,25	30	14,0	4,40	5,0	200	-	34,87 €

Dimensions in mm

Our other products



PR580

Stainless steel articulated foot $\varnothing 80$, $\varnothing 80$



AC156-157

Strike for toggle latch, 25.5mm



 
H0

Crossed helical gear crossed axis at 90° , Steel 20NCD2



DB

Steel bevel gear, 2:1



T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



BS2

Panamech, Multi-Beam, Aluminium - with set screw



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis



DB

Steel bevel gear, 2:1



PLM-C

Cylindrical holding magnets, Cylindrical



 
FHCSS

Countersunk screw, Stainless steel A2 -



ES

Simple support base (bipod), Plastic



DOMI_MD

Domino rotary table, 55/1

Complementary products



 
SHN

Hexagonal nut DIN934, A2 Stainless steel



ACL-PR

Joining plate for aluminium profile, Right angled connection



ACL-PR

Joining plate for aluminium profile, Right angled connection



ACL-PLAngle

Joining plate for aluminium profile, Angle connection