

Socket head button screw **ISO 7380** **Stal** **ISO**


BHC

Stainless steel A2

- **Conforms to ISO 7380**
- **Material:**
stainless steel 302/304-A2
- Hexagonal socket

Info.

- Supplied by pack

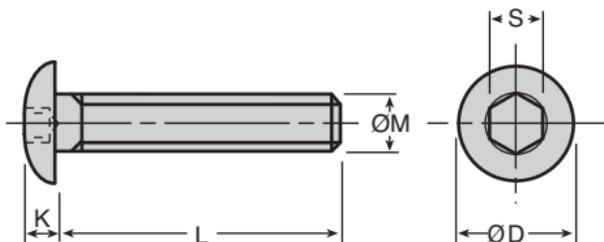

DISCOUNTS

N° packets	1+	2+	4+
Discounts	List	-20%	On request

Part number	Thread	Pitch	Length	ØD	K	S	Qty. per packet	Stock*	Price per packet
	ØM		L						
BHC4-8/SS/B	M4	0,70	8	7,6	2,20	2,5	500	✓	27,49 €
BHC4-10/SS/B	M4	0,70	10	7,6	2,20	2,5	500	✓	33,55 €
BHC4-12/SS/B	M4	0,70	12	7,6	2,20	2,5	500	✓	32,40 €
BHC4-16/SS/B	M4	0,70	16	7,6	2,20	2,5	500	-	20,87 €
BHC5-10/SS/B	M5	0,80	10	9,5	2,75	3,0	500	✓	22,29 €
BHC5-12/SS/B	M5	0,80	12	9,5	2,75	3,0	500	✓	30,97 €
BHC5-16/SS/B	M5	0,80	16	9,5	2,75	3,0	500	-	33,81 €
BHC5-20/SS/B	M5	0,80	20	9,5	2,75	3,0	500	✓	36,98 €
BHC6-12/SS/B	M6	1,00	12	10,5	3,30	4,0	500	✓	34,34 €
BHC6-16/SS/B	M6	1,00	16	10,5	3,30	4,0	500	-	41,07 €
BHC6-20/SS/B	M6	1,00	20	10,5	3,30	4,0	500	✓	47,61 €
BHC6-25/SS/B	M6	1,00	25	10,5	3,30	4,0	500	-	67,04 €
BHC8-16/SS/B	M8	1,25	16	14,0	4,40	5,0	200	✓	37,03 €
BHC8-20/SS/B	M8	1,25	20	14,0	4,40	5,0	200	✓	35,40 €
BHC8-25/SS/B	M8	1,25	25	14,0	4,40	5,0	200	-	50,10 €
BHC8-30/SS/B	M8	1,25	30	14,0	4,40	5,0	200	-	56,38 €

*Depending on availability - Dimensions in mm