
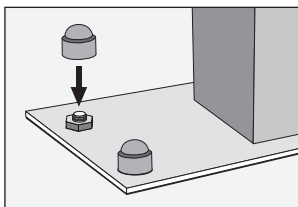


Hexagonal cap

BHEX

For hexagonal heads

- Cap for hexagonal headed screws or nuts
- Stylish, avoids risks of cuts
- Material:
Black technopolymer
- Supplied by the pack

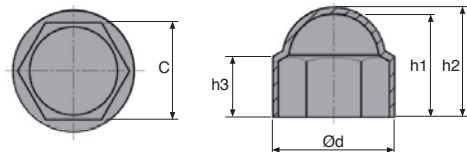

Typical application

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-10%	-20%	On request

Part number	For thread	Size of hexagon	C	Ød	h1	h2	h3	Qty per pack	Stock*	Price each 1 to 4
BHEX-4/B	M4	7	6,9	9	7,5	8,3	3,5	100	-	18,60 €
BHEX-5/B	M5	8	7,9	10,9	8,5	9,5	5	100	✓	18,60 €
BHEX-6/B	M6	10	9,8	12,9	12,0	13,0	6	100	✓	18,60 €
BHEX-8/B	M8	13	12,8	16,8	14,0	15,0	9	100	✓	26,04 €
BHEX-10/B	M10	17	16,7	21,3	18,5	19,5	9	50	✓	14,88 €
BHEX-12/B	M12	19	18,7	23,6	20,0	21,5	11	50	✓	18,60 €
BHEX-14/B	M14	22	21,7	27,5	22,5	24,0	12	50	-	20,46 €
BHEX-16/B	M16	24	23,7	29,8	25,5	27,0	14	10	✓	7,06 €
BHEX-20/B	M20	30	29,8	37,7	31,0	33,2	17	10	✓	17,84 €
BHEX-24	M24	36	35,8	4,4	38,0	39,2	20	1	-	2,29 €
BHEX-30	M30	46	45,8	55,9	49,0	51,5	25	1	-	3,34 €

Dimensions in mm

Our other products



OP3_14_06
Reducing sleeve for
OP indicators,
Reduction socket



BSM
Spring plunger with
internal hexagonal
socket, steel body,
plastic pin



PM2
Worm and wheel set,
Machined plastic
(delrin)



PTAF80-PAMF80
Articulated fixable
foot with pressed
base Ø80, Ø 80




BFM
Flanged bronze nut,
Bronze - 1 thread



RJUM05
Drylin R® linear
bearing housing,
Closed - Long



JCDss
Double universal joint
- Stainless steel, Low
duty

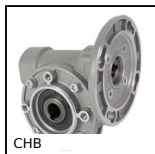

CHB
Worm and wheel gear
reducer, up to 73 Nm



BPPss
Pressed stainless
steel pillow block,
Stainless steel



SHA
Handwheel without
handle, Polyamide



BSPT
Single rod clip, Round



AFSE
Locking pin with
interlocking safety
latch, with
interlocking safety...

Complementary products



VTH
Hexagonal headed
bolts, Steel class 8.8



SHN
Hexagonal nut
DIN934, Steel (Class
6[8])