
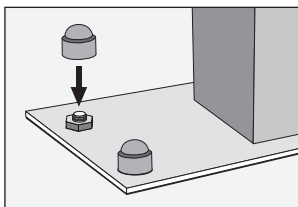


# Hexagonal cap

## BHEX

## For hexagonal heads

- Cap for hexagonal headed screws or nuts
- Stylish, avoids risks of cuts
- Material:  
Black technopolymer
- Supplied by the pack

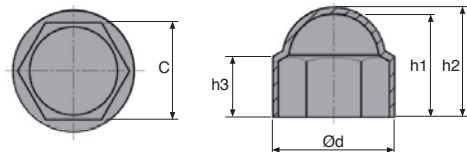

Typical application

### DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-10%	-20%	On request

Part number	For thread	Size of hexagon	C	Ød	h1	h2	h3	Qty per pack	Stock*	Price each 1 to 4
BHEX-4/B	M4	7	6,9	9	7,5	8,3	3,5	100	-	18,60 €
BHEX-5/B	M5	8	7,9	10,9	8,5	9,5	5	100	✓	18,60 €
BHEX-6/B	M6	10	9,8	12,9	12,0	13,0	6	100	✓	18,60 €
BHEX-8/B	M8	13	12,8	16,8	14,0	15,0	9	100	✓	26,04 €
BHEX-10/B	M10	17	16,7	21,3	18,5	19,5	9	50	✓	14,88 €
BHEX-12/B	M12	19	18,7	23,6	20,0	21,5	11	50	✓	18,60 €
BHEX-14/B	M14	22	21,7	27,5	22,5	24,0	12	50	-	20,46 €
BHEX-16/B	M16	24	23,7	29,8	25,5	27,0	14	10	✓	7,06 €
BHEX-20/B	M20	30	29,8	37,7	31,0	33,2	17	10	✓	17,84 €
BHEX-24	M24	36	35,8	4,4	38,0	39,2	20	1	-	2,29 €
BHEX-30	M30	46	45,8	55,9	49,0	51,5	25	1	-	3,34 €

Dimensions in mm

## Our other products



End cap for rectangular tube, Standard



Closed linear precision bearing, Economy range



Idler for slat top chain, Ranges 820 and 815



Lock for aluminium profile, Quick fitting, self locking door lock



Captive C washer, DIN 6371



 
Universal joint, telescopic, Inox, Light duty



Conical compression spring, Conical



Offset spur gear reducer, from 111 to 425 Nm



Automatic chain tensioner, With 180° guide



Adjustable suction-cup support, Standard grip



Linear roller slide, Chariot - from 9410 N to 101000 N



Hardened Stainless steel ball pin, Hardened stainless steel

## Complementary products



Hexagonal headed bolts, Steel class 8.8



Hexagonal nut, DIN934, Steel (Class 6[8])