
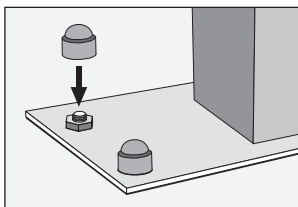


Hexagonal cap

BHEX

For hexagonal heads

- Cap for hexagonal headed screws or nuts
- Stylish, avoids risks of cuts
- Material:
Black technopolymer
- Supplied by the pack

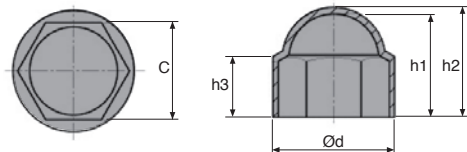

Typical application

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-10%	-20%	On request

Part number	For thread	Size of hexagon	C	Ød	h1	h2	h3	Qty per pack	Stock*	Price each 1 to 4
BHEX-4/B	M4	7	6,9	9	7,5	8,3	3,5	100	-	18,60 €
BHEX-5/B	M5	8	7,9	10,9	8,5	9,5	5	100	✓	18,60 €
BHEX-6/B	M6	10	9,8	12,9	12,0	13,0	6	100	✓	18,60 €
BHEX-8/B	M8	13	12,8	16,8	14,0	15,0	9	100	✓	26,04 €
BHEX-10/B	M10	17	16,7	21,3	18,5	19,5	9	50	✓	14,88 €
BHEX-12/B	M12	19	18,7	23,6	20,0	21,5	11	50	✓	18,60 €
BHEX-14/B	M14	22	21,7	27,5	22,5	24,0	12	50	-	20,46 €
BHEX-16/B	M16	24	23,7	29,8	25,5	27,0	14	10	✓	7,06 €
BHEX-20/B	M20	30	29,8	37,7	31,0	33,2	17	10	✓	17,84 €
BHEX-24	M24	36	35,8	4,4	38,0	39,2	20	1	-	2,29 €
BHEX-30	M30	46	45,8	55,9	49,0	51,5	25	1	-	3,34 €

Dimensions in mm

Our other products



BABTV
Ball lock pins lockable
, Stainless steel



WS20
Drylin® W rail, Rail



UCFL_PBT
Stainless
steel/Polymer flanged
bearing, Polymer and
stainless steel



ACLAPA
Magnetic stop for
aluminium profile,
Magnetic stop



PRF_BASE
Base plate for
aluminium profile,
Base plate



PR40
Articulated foot Ø40,
Ø 40



ADL_M
Male eye bolt
conforms to DIN580,
Steel



SC2
2 part rigid shaft
clamp, Clamping jaw



CHAEss
Decorative hinge,
Stainless steel



CLLCLLP
Clevis components,
long version, Steel -
long version



RPCtc
Swivel castor with
central hole, Steel -
Polyamide - with



NKIA
Combined bearing
with inner ring, Axial
load in one direction

Complementary products



VTH
Hexagonal headed
bolts, Steel class 8.8



SHN
Hexagonal nut
DIN934, Steel (Class
6[8])