
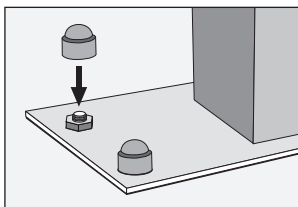


# Hexagonal cap

## BHEX

## For hexagonal heads

- Cap for hexagonal headed screws or nuts
- Stylish, avoids risks of cuts
- Material:  
Black technopolymer
- Supplied by the pack

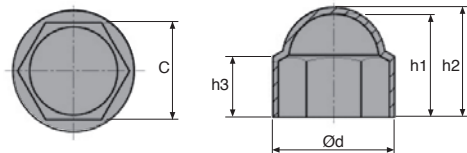

Typical application

### DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-10%	-20%	On request

Part number	For thread	Size of hexagon	C	Ød	h1	h2	h3	Qty per pack	Stock*	Price each 1 to 4
BHEX-4/B	M4	7	6,9	9	7,5	8,3	3,5	100	-	18,60 €
BHEX-5/B	M5	8	7,9	10,9	8,5	9,5	5	100	✓	18,60 €
BHEX-6/B	M6	10	9,8	12,9	12,0	13,0	6	100	✓	18,60 €
BHEX-8/B	M8	13	12,8	16,8	14,0	15,0	9	100	✓	26,04 €
BHEX-10/B	M10	17	16,7	21,3	18,5	19,5	9	50	✓	14,88 €
BHEX-12/B	M12	19	18,7	23,6	20,0	21,5	11	50	✓	18,60 €
BHEX-14/B	M14	22	21,7	27,5	22,5	24,0	12	50	-	20,46 €
BHEX-16/B	M16	24	23,7	29,8	25,5	27,0	14	10	✓	7,06 €
BHEX-20/B	M20	30	29,8	37,7	31,0	33,2	17	10	✓	17,84 €
BHEX-24	M24	36	35,8	4,4	38,0	39,2	20	1	-	2,29 €
BHEX-30	M30	46	45,8	55,9	49,0	51,5	25	1	-	3,34 €

Dimensions in mm

## Our other products



PRF4545  
Standard aluminium  
profile, 45 x 45 mm



CHAC4040SS  
Square hinge with  
riveted pin, drilled,  
Square with riveted  
pin, dri...



T5-16ECO  
T type timing pulley,  
Economy range - T5  
aluminium



DER90  
Stainless steel AC  
asynchronous motor  
1.1 - 1.5kW, 1.1 to  
1.5kW



M0  
Worm and wheel set,  
Bronze



VCMB  
Dual-thread screw  
wood/metal, Steel



CHM50-MOT  
Asynchronous AC  
motorgearboxes 0.18  
to 0.75kW, 0.18 to  
0.75kW



BPPE  
Ball transfer unit push  
fit, Light




CHAL3  
Piano hinge,  
Aluminium



CLM  
Male clevis end,  
Stainless steel short



 SLB  
Indexing plunger,  
steel class 5.8



H0  
Crossed helical gear  
crossed axis at 90°,  
Machined plastic  
(delrin)

## Complementary products



VTH  
Hexagonal headed  
bolts, Steel class 8.8



SHN  
Hexagonal nut  
DIN934, Steel (Class  
6|8)