

BLM

Ball tip

- **Plunger for positioning and locating**

- **Materials:**

Body: Stainless steel or


thermosetting plastic

Spring: Stainless steel

Ball: Stainless steel or Delrin



Ball stainless steel or Delrin

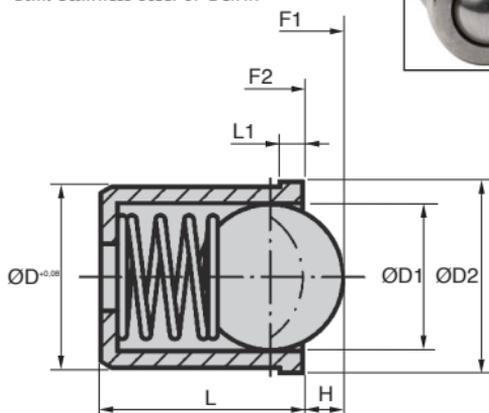

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+	400+
Disc.	List	-5%	-10%	-15%	-25%	-40%	On request

Part number	Ball	ØD	ØD1	ØD2	L	L1	H	Contact pressure		Weight (g)	Stock*	Price each 1 to 5
								initial F1 (N)	final F2 (N)			
Stainless steel body												
BLM5SS	Stainless steel	5	4	5,6	6	1	1,0	4	7	0,60	✓	1,94 €
BLM6SS	Stainless steel	6	5	6,5	7	1	1,5	6	12	1,00	✓	2,07 €
BLM8SS	Stainless steel	8	6,5	8,5	9	1	1,8	6	12	2,00	✓	2,55 €
BLM10SS	Stainless steel	10	8	12,0	13,5	2,5	2,7	10	20	6,00	✓	3,30 €
BLM5P	Delrin	5	4	5,6	6	1	0,6	4	7	0,60	✓	2,24 €
BLM6P	Delrin	6	5	6,5	7	1	1,1	6	12	1,00	✓	2,29 €
BLM8P	Delrin	8	6,5	8,5	9	1	1,5	6	12	2,00	✓	2,86 €
BLM10P	Delrin	10	8	12,0	13,5	2,5	2,3	10	20	6,00	✓	3,61 €
Plastic body												
BLM5PS	Stainless steel	5	4	5,6	6	1	1,0	4	7	0,40	-	1,17 €
BLM6PS	Stainless steel	6	5	6,5	7	1	1,5	6	12	0,70	✓	1,35 €
BLM8PS	Stainless steel	8	6,5	8,5	9	1	1,8	6	12	1,50	✓	1,52 €
BLM10PS	Stainless steel	10	8	12,0	13,5	2,5	2,7	10	20	3,14	✓	2,86 €
BLM5PP	Delrin	5	4	5,6	6	1	1,2	4	7	0,35	✓	1,36 €
BLM6PP	Delrin	6	5	6,5	7	1	1,5	6	12	0,66	✓	1,47 €
BLM8PP	Delrin	8	6,5	8,5	9	1	2	6	12	1,46	✓	1,75 €
BLM10PP	Delrin	10	8	12,0	13,5	2,5	2,7	10	20	1,44	✓	3,37 €

*Depending on availability - Dimensions in mm