

# Spring loaded plunger

Stock DelSta

## BLM

## Ball tip


- **Plunger for positioning and locating**

- **Materials :**

Body: Stainless steel or thermosetting plastic

Spring: Stainless steel

Ball: Stainless steel or Delrin

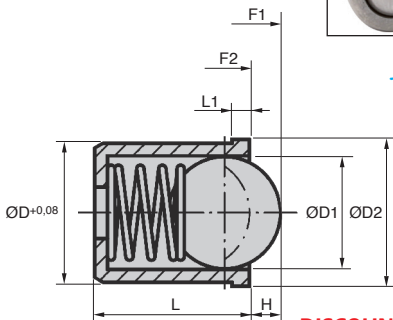

Ball stainless steel or Delrin

### DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+	400+
Disc.	List	-5%	-10%	-15%	-20%	-25%	On request

Part number	Ball	ØD	ØD1	ØD2	L	L1	H	Contact Pressure		Weight (g)	Stock*	Price each 1 to 5
								Initial F1 (N)	Final F2 (N)			
<b>Stainless steel body</b>												
BLM5SS	Stainless steel	5	4	5,6	6	1	1,0	4	7	0,60	✓	1,68 €
BLM6SS	Stainless steel	6	5	6,5	7	1	1,5	6	12	1,00	✓	1,80 €
BLM8SS	Stainless steel	8	6,5	8,5	9	1	1,8	6	12	2,00	✓	2,23 €
BLM10SS	Stainless steel	10	8	12,0	13,5	2,5	2,7	10	20	6,00	✓	2,88 €
BLM5P	Delrin	5	4	5,6	6	1	0,6	4	7	0,60	✓	1,96 €
BLM6P	Delrin	6	5	6,5	7	1	1,1	6	12	1,00	✓	2,00 €
BLM8P	Delrin	8	6,5	8,5	9	1	1,5	6	12	2,00	✓	2,52 €
BLM10P	Delrin	10	8	12,0	13,5	2,5	2,3	10	20	6,00	✓	3,16 €
<b>Plastic body</b>												
BLM5PS	Stainless steel	5	4	5,6	6	1	1,0	4	7	0,40	-	1,03 €
BLM6PS	Stainless steel	6	5	6,5	7	1	1,5	6	12	0,70	✓	1,15 €
BLM8PS	Stainless steel	8	6,5	8,5	9	1	1,8	6	12	1,50	✓	1,34 €
BLM10PS	Stainless steel	10	8	12,0	13,5	2,5	2,7	10	20	3,14	✓	2,52 €
BLM5PP	Delrin	5	4	5,6	6	1	1,2	4	7	0,35	✓	1,20 €
BLM6PP	Delrin	6	5	6,5	7	1	1,5	6	12	0,66	✓	1,30 €
BLM8PP	Delrin	8	6,5	8,5	9	1	2	6	12	1,46	✓	1,55 €
BLM10PP	Delrin	10	8	12,0	13,5	2,5	2,7	10	20	1,44	✓	2,94 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



KKP-AR

Linear bearing with inclined ball tracks, Heavy loads /  $-20^{\circ}$   $+200^{\circ}$



E20

Right angle helical reducers, from 0.60 to 3.84 Nm



H5

Hexagonal spacer, Stainless steel 303



EPRC

High helix leadscrew, Cylindrical nut - up to 40mm per rotation



 
PMB

Anti-vibration machine mount, Oval base plate



CHT

Asynchronous AC motor, 0.09kW



QNJ

Single row cylindrical roller bearing, Single flange on inner ring



TPEF

Castor for aluminium profile, Fixed



BS2

Panamech, Multi-Beam, Aluminium -



AC144

Strike for toggle latch, 22mm



HBM

Adjustment bushing for half-rail guide,



LC

Friction clutch, 190 to 1800 Nm

## Complementary products



BLM

Spring loaded plunger with ball tip, Plastic body



BPM\_LOK

Long-Lok slotted spring plunger with ball tip, LONG-LOK - Stainless ...



BPM

Slotted spring plunger with ball tip, Stainless steel 303



BPM-Z

Plastic slotted spring plunger with ball tip, Plastic body + stainle...