

# Spring loaded plunger

Stock DelSta

## BLM

## Ball tip


- **Plunger for positioning and locating**

- **Materials :**

Body: Stainless steel or thermosetting plastic

Spring: Stainless steel

Ball: Stainless steel or Delrin

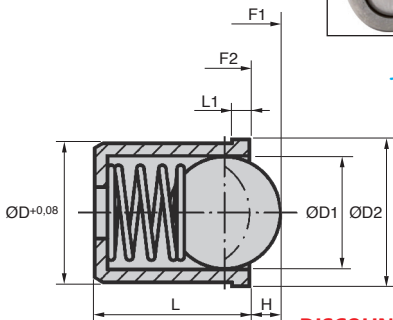

Ball stainless steel or Delrin

### DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+	400+
Disc.	List	-5%	-10%	-15%	-20%	-25%	On request

Part number	Ball	ØD	ØD1	ØD2	L	L1	H	Contact Pressure		Weight (g)	Stock*	Price each 1 to 5
								Initial F1 (N)	Final F2 (N)			
<b>Stainless steel body</b>												
BLM5SS	Stainless steel	5	4	5,6	6	1	1,0	4	7	0,60	✓	1,68 €
BLM6SS	Stainless steel	6	5	6,5	7	1	1,5	6	12	1,00	✓	1,80 €
BLM8SS	Stainless steel	8	6,5	8,5	9	1	1,8	6	12	2,00	✓	2,23 €
BLM10SS	Stainless steel	10	8	12,0	13,5	2,5	2,7	10	20	6,00	✓	2,88 €
BLM5P	Delrin	5	4	5,6	6	1	0,6	4	7	0,60	✓	1,96 €
BLM6P	Delrin	6	5	6,5	7	1	1,1	6	12	1,00	✓	2,00 €
BLM8P	Delrin	8	6,5	8,5	9	1	1,5	6	12	2,00	✓	2,52 €
BLM10P	Delrin	10	8	12,0	13,5	2,5	2,3	10	20	6,00	✓	3,16 €
<b>Plastic body</b>												
BLM5PP	Stainless steel	5	4	5,6	6	1	1,0	4	7	0,40	-	1,03 €
BLM6PS	Stainless steel	6	5	6,5	7	1	1,5	6	12	0,70	✓	1,15 €
BLM8PS	Stainless steel	8	6,5	8,5	9	1	1,8	6	12	1,50	✓	1,34 €
BLM10PS	Stainless steel	10	8	12,0	13,5	2,5	2,7	10	20	3,14	✓	2,52 €
BLM5PP	Delrin	5	4	5,6	6	1	1,2	4	7	0,35	✓	1,20 €
BLM6PP	Delrin	6	5	6,5	7	1	1,5	6	12	0,66	✓	1,30 €
BLM8PP	Delrin	8	6,5	8,5	9	1	2	6	12	1,46	✓	1,55 €
BLM10PP	Delrin	10	8	12,0	13,5	2,5	2,7	10	20	1,44	✓	2,94 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



LRM  
Trapezoidal bronze nut, Bronze - 1 thread



HG5-ECO  
Eco range Spur gear, Steel C45



HRV  
V-rail guidance Simple Select® system, Rail with carriage




ACLERP  
Roller block for aluminium profile, With guide rail



HS  
Hexagonal spacer, Stainless steel 303



 PM4  
Worm and wheel set, Machined plastic (delrin)



PF40  
Worm and wheel gear reducer, up to 18 Nm



PAV  
Fixed anti-vibration foot mount, Vibration-dampening




PHT  
Pull handle, Up to 250 °C



M0  
Worm and wheel set, Non hardened steel



SH3  
Parallel axis helical gear, Machined plastic (delrin)

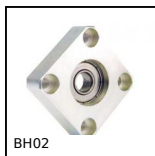

BH02  
Single housed bearing assembly, Bearing secured with circlips

## Complementary products



BLM  
Spring loaded plunger with ball tip, Plastic body



BPM\_LOK  
Long-Lok slotted spring plunger with ball tip, LONG-LOK - Stainless ...



BPM  
Slotted spring plunger with ball tip, Stainless steel 303



BPM-Z  
Plastic slotted spring plunger with ball tip, Plastic body + stainle...