

# Knurled knob, male

**BMM** Technopolymer, steel or **stainless steel** stud


**- Small fixing knob**

**- Materials:**

Black polyamide, matt surface finish  
Threaded stud: chromed steel  
or stainless steel

**Info**

- Can be used with **BMF** female knurled knobs to make a manual bolted assembly

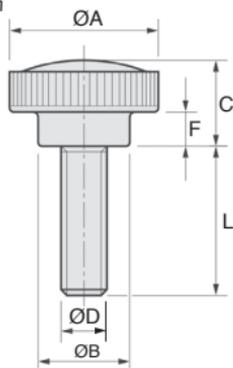

steel or stainless steel stud

**DISCOUNTS**

Qty	1+	10+	20+	50+	100+	200+
Disc.	Net	-5%	-10%	-15%	-20%	On request

Part number									Weight	Price each 1 to 9	
Steel	Stainless steel	ØA	ØB	C	ØD	L	F	(g)	Steel	Stainless steel	
BMM15-M4-10		15	11	14	M4	10	7	4	1,33 €		
BMM15-M4-15		15	11	14	M4	15	7	4	1,42 €		
BMM15-M5-10		15	11	14	M5	10	7	4	1,37 €		
BMM22-M4-10		22	15	14	M4	10	6	6	1,42 €		
BMM22-M4-25		22	15	14	M4	25	6	6	1,50 €		
BMM22-M5-10	BMM22-M5-10/SS	22	15	14	M5	10	6	7	1,42 €	3,75 €	
BMM22-M5-15		22	15	14	M5	15	6	7	1,42 €		
BMM22-M6-10		22	15	14	M6	10	6	8	1,50 €		
BMM22-M6-20		22	15	14	M6	20	6	9	1,50 €		
BMM22-M6-30		22	15	14	M6	30	6	11	1,61 €		
BMM22-M6-40		22	15	14	M6	40	6	13	1,66 €		
BMM26-M5-10		26	16	15	M5	10	6	9	1,66 €		
BMM26-M5-25		26	16	15	M5	25	6	11	1,66 €		
BMM26-M6-10		26	16	15	M6	10	6	10	1,66 €		
BMM26-M6-20	BMM26-M6-20/SS	26	16	15	M6	20	6	12	1,66 €	3,88 €	
BMM26-M6-40		26	16	15	M6	40	6	15	1,75 €		
BMM26-M8-25		26	16	15	M8	25	6	17	1,84 €		
BMM32-M6-20		32	19	18	M6	20	8	14	1,84 €		
BMM32-M6-40		32	19	18	M6	40	8	18	1,94 €		
BMM32-M8-15		32	19	18	M8	15	8	19	2,03 €		
BMM32-M8-40		32	19	18	M8	40	8	27	2,17 €		

All dimensions in mm

# Knurled knob, female

Technopolymer, brass insert

BMF

**- Small fixing knob**

**- Materials:**

Black polyamide, matt surface finish


Brass insert

**Info**

- Can be used with **BMM** male knurled knobs to make a manual bolted assembly



Brass insert

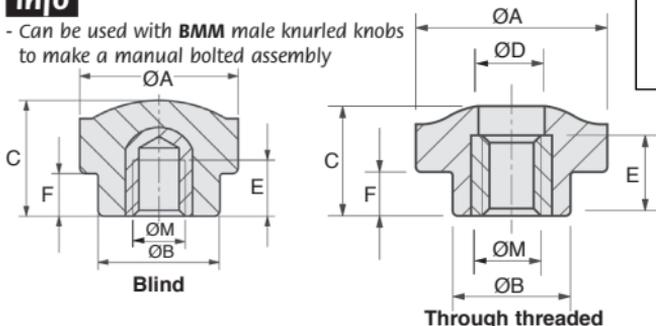

**DISCOUNTS**

Qty	1+	10+	20+	50+	100+	200+
Disc.	Net	-5%	-10%	-15%	-20%	On request

Part number	ØA	ØB	C	ØM	ØD	E	F	Weight (g)	Price each
									1 to 9
<b>Blind</b>									
BMF15-M4	15	11	14	M4	-	9	7	4	1,46 €
BMF15-M5	15	11	14	M5	-	9	7	4	1,50 €
BMF22-M5	22	15	14	M5	-	8	6	8	1,71 €
BMF22-M6	22	15	14	M6	-	8	6	8	1,71 €
BMF22-M8	22	15	14	M8	-	8	6	7	1,84 €
BMF26-M5	26	16	15	M5	-	8	6	11	1,75 €
BMF26-M6	26	16	15	M6	-	8	6	11	1,90 €
BMF26-M8	26	16	15	M8	-	8	6	10	1,90 €
BMF32-M6	32	19	18	M6	-	9	8	13	1,94 €
BMF32-M8	32	19	18	M8	-	9	8	14	2,03 €
<b>Through threaded</b>									
BMF15-M4/FP	15	11	14	M4	7	11	7	4	2,07 €
BMF15-M5/FP	15	11	14	M5	7	11	7	4	2,17 €
BMF22-M5/FP	22	15	14	M5	9	11	6	7	2,27 €
BMF22-M6/FP	22	15	14	M6	9	11	6	7	2,31 €
BMF22-M8/FP	22	15	14	M8	9	11	6	7	2,35 €
BMF26-M5/FP	26	16	15	M5	9	11	6	9	2,35 €
BMF26-M6/FP	26	16	15	M6	9	11	6	9	2,40 €
BMF26-M8/FP	26	16	15	M8	9	11	6	9	2,40 €
BMF32-M6/FP	32	19	18	M6	9	11	8	11	2,44 €
BMF32-M8/FP	32	19	18	M8	9	11	8	12	2,49 €

All dimensions in mm