

Box set of hose clamps

BOX-CS

Steel

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

Info.

- Also contains a flexible screwdriver



Small version BOX-CS-100

Quantity	Range of adjustment Ø	Collar width
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

Large version BOX-CS-220

Quantity	Range of adjustment Ø	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%		On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100	255x315x65	100 clamps	59,84 €
BOX-CS-220	460x360x85	220 clamps	124,68 €

All dimensions in mm

Our other products



MDB_MTB
Moulded plastic bevel gear (nylon), 2:1




PRF_PSA
Shaft support for aluminium profile, Linear guide shaft



EX
Optional shaft for E-type gear reducers, E Gearboxes single sided out...



HTD5M_25
HTD Heavy duty timing pulley, HTD5 Steel

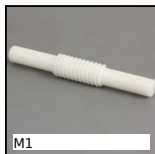

M1
Worm and wheel set, Machined plastic (delrin)



PGMSS
Stainless steel pull handle, Stainless steel



PRF-SCREEN-1
Screen support, Basic support



GMK17_R
Round guide, Round guide for conical profile



HS
Hexagonal spacer, Stainless steel 303



PR40
Articulated foot Ø50, Ø 50



GLP
Small 6 lobe threaded handle - male, Technopolymer - Steel



RAG-12-M8
Roller guide accessory, Anchoring system

Complementary products



BOX-CSss
Hose clamp, Box set of stainless steel hose clamps