

# Box set of hose clamps

Stainless steel

BOX-CS/SS

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

## Info.

- Also contains a flexible screwdriver



stainless steel



### Small version BOX-CS-100/SS

Quantity	Range of serrage Ø	largeur bande
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

### Large version BOX-CS-220/SS

Quantity	Range of adjustment Ø	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

## DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%	-5%	On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100/SS	255x315x65	100 clamps	97,25 €
BOX-CS-220/SS	460x360x85	220 clamps	184,03 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

207

## Our other products



PRF-SCREEN-4

Screen support,  
Support with 4 axes of  
rotation




AT5-10ECO

AT type timing pulley,  
Economy range - AT5  
aluminium



HRV

V- rail guidance  
Simple Select®  
system, Rail with  
carriage

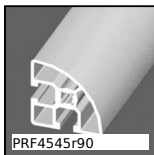

PRF4545r90

Standard aluminium  
profile, 45 x 45 mm -  
R90°



 
ZDB

Machined plastic  
bevel gear , 2:1



G1

Steel spur gear, Steel  
20NCD2



PM4

Worm and wheel set,  
Bronze




PM4

Worm and wheel set,  
Machined plastic  
(delrin)



BLH40

 Right angled gearbox,  
from 3 to 10.30 Nm



ZR

Plastic rack, Delrin



GE

Toggle latches,  
Miniature



M0

Worm and wheel set,  
Non hardened steel

## Complementary products



BOX-CS

Hose clamp, Box set  
of steel hose clamps