

# Boxed set of wide threaded self tapping inserts

For wood

BOX-INS-W

- Selection of self tapping inserts with a large external thread for use in wood
- Assembles by deformation, no special tools required
- With hexagonal socket for assembly
- Material:  
White galvanized steel

## Applications

- Can be used in soft plastics or woods and rubber



480 pieces




010

440

002

006

Quantity	Type	ØD	L	Ød	SW
50	010	10	12	M5	5
50	010	12	15	M6	6
30	010	14	15	M8	8
50	440	10	12	M5	5
50	440	12	12	M6	6
30	440	14	15	M8	8
50	002	10	10	M5	-
50	002	12	15	M6	-
30	002	14	14	M8	-
30	006	8	12	M5	-
30	006	15	15	M6	-
30	006	12	15	M8	-

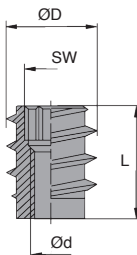

## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Quantity per box	Price each
BOX-INS-W	480 pieces	373,29 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 €/min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

205

## Our other products



HRV

V-rail guidance  
Simple Select®  
system, Rail with  
carriage



SLB

Indexing plunger,  
stainless steel



AT5P\_AT10P

Connecting plate for  
AT type timing belts,  
AT10



SUPTOOL

Installation tools for  
clamping hub, For  
hexagonal clamping  
hub



SCE\_SS

Stainless steel U-  
shaped clamp,  
Stainless steel



MHSC

Single-disc flexible  
coupling, Single disk



PCS50

Chain sprocket - steel,  
12.7mm (DIN08B-1)



DOM80

Accessories, Clamping  
lever



GLB

Small 6-lobe female  
handle,



PAT123

Pressed stainless  
steel articulating foot



ACM\_AZ

Mounting bracket for  
bonnet fastener, Hook



PR125

Articulated foot Ø123,  
Ø 123

## Complementary products



INS100

Self tapping inserts-  
coarse thread, Coarse  
thread



INS150

Self tapping insert  
with collar-coarse  
thread, With collar-  
coarse t...



BOXINS300

Box set of self tapping  
inserts, Boxed set -  
For hard materials