

Boxed set of wide threaded self tapping inserts

For wood

BOX-INS-W

- Selection of self tapping inserts with a large external thread for use in wood
- Assembles by deformation, no special tools required
- With hexagonal socket for assembly
- Material:
White galvanized steel

Applications

- Can be used in soft plastics or woods and rubber



480 pieces




010

440

002

006

Quantity	Type	ØD	L	Ød	SW
50	010	10	12	M5	5
50	010	12	15	M6	6
30	010	14	15	M8	8
50	440	10	12	M5	5
50	440	12	12	M6	6
30	440	14	15	M8	8
50	002	10	10	M5	-
50	002	12	15	M6	-
30	002	14	14	M8	-
30	006	8	12	M5	-
30	006	15	15	M6	-
30	006	12	15	M8	-

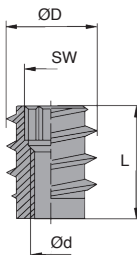

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Quantity per box	Price each
BOX-INS-W	480 pieces	373,29 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

205

Our other products



ACL-PL

Joining plate for aluminium profile, joint plate - 86x86 mm



Q1

Self-aligning radial ball bearing, Steel



AT5P_AT10P

Connecting plate for AT type timing belts, AT10



G3-ECO

Eco range Spur gear, Steel C45



P45

Worm and wheel gear reducer, up to 40 Nm



PFM

Fixed levelling foot, Flanged plate



PFC

Fixed rubber levelling foot, Levelling support for small parts



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



CHTRB

Single and dual output gearboxes, Up to 16,5 Nm



DBL805

Idler for slat top chain, Range 805



H4

Crossed helical gear crossed axis at 90°, Steel 20NCD2



NSU

Universal 90° support clamp, Universal 90° support clamp

Complementary products



INS100

Self tapping inserts-coarse thread, Coarse thread



INS150

Self tapping insert with collar-coarse thread, With collar-coarse t...



BOXINS300

Box set of self tapping inserts, Boxed set - For hard materials