

# Box sets of self-locking nuts **DIN985**

## BOX-NINA

Steel

- Boxes of standard DIN985 self-locking nuts

### Application

- Ideal for the maintenance department  
or for use in workshops



- Box details

Quantity	Thread ØM	Thread
<b>Standard thread</b>		
100	M4	0,70
100	M5	0,80
100	M6	1,00
50	M8	1,25
50	M10	1,50
25	M12	1,75
10	M14	2,00
10	M16	2,00
<b>Fine thread</b>		
50	M10	1,00
25	M12	1,50
20	M14	1,50
10	M16	1,50

### DISCOUNTS

Qty	1+	2+	5+
Disc.	Prix	-5%	On request

Part N°	Quantity per box	Price each
BOX-NINA	550 washers	75,50 €

## Our other products



PSG2

Spur gear - precision range, Pre-hardened Steel 35NCD6



ACL-PR

Joining plate for aluminium profile, Right angled connection



M0

Worm , Non hardened steel



ACLEPP

Right angled bracket for aluminium profile, 4 holes



NPTF30

Spacer for tube carrier, Fixing accessory  $\varnothing 14$  to  $\varnothing 20$



HTD14M\_85

HTD Heavy duty timing pulley, HTD14 Steel



CHA225

Screwed hinge with threaded insert, 225 degrees



SLS

Bearing block for leadscrew, Floating Drylin® bearing block




BKGS

Backlash free coupling Gerwah®, from 1.2 to 450Nm



NPTR10

Adjustable cross clamp, Adjustable

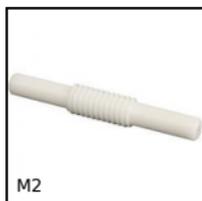

M2

Worm , Machined plastic (delrin)



E50

Right angle helical reducers, from 3 to 41 Nm

## Complementary products



NIN

Self-locking nut, Steel



BOX-SHNA

Hexagonal nut - DIN934, Box set of steel nuts



BOX-WM

Box set of washer - DIN125, Box set of steel washers