

# Box sets of self-locking nuts **DIN985**

## BOX-NINA

Steel

- Boxes of standard DIN985 self-locking nuts

### Application

- Ideal for the maintenance department  
or for use in workshops



- Box details

Quantity	Thread ØM	Thread
<b>Standard thread</b>		
100	M4	0,70
100	M5	0,80
100	M6	1,00
50	M8	1,25
50	M10	1,50
25	M12	1,75
10	M14	2,00
10	M16	2,00
<b>Fine thread</b>		
50	M10	1,00
25	M12	1,50
20	M14	1,50
10	M16	1,50

### DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%		On request

Part N°	Quantity per box	Price each
BOX-NINA	550 washers	75,50 €

## Our other products



DOMI\_MD

Domino rotary table,  
40/1



CLAT

Clamping lever  
Hygienic Usit® -  
male, Stainless steel



AXTR

Axle for tensioner  
pulley, Shaft



PCF4

Conical flexible  
mount, Square base  
plate



SSB

Stainless steel bevel  
gear, 1:1



Gal-cardan

Single universal joint  
eco series, Low duty



PR85

Articulated foot Ø83,  
Ø 83



DOMI30

Accessories, Plate




BAG

Steel Clamping collar,  
Steel



PSG125S

Spur gear - precision  
range, Stainless steel  
303

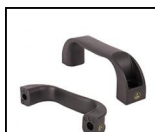

PAS

Pull handle,  
Reinforced PA  
thermoplastic



CHAM5270SS

Marine hinge for  
welding/screw  
mounting, Marine

## Complementary products



NIN

Self-locking nut, Steel



BOX-SHNA

Hexagonal nut -  
DIN934, Box set of  
steel nuts



BOX-WM

Box set of washer -  
DIN125, Box set of  
steel washers