

Box sets of self-locking nuts **DIN985**

BOX-NINA

Steel

- Boxes of standard DIN985 self-locking nuts

Application

- Ideal for the maintenance department
or for use in workshops



- Box details

Quantity	Thread ØM	Thread
Standard thread		
100	M4	0,70
100	M5	0,80
100	M6	1,00
50	M8	1,25
50	M10	1,50
25	M12	1,75
10	M14	2,00
10	M16	2,00
Fine thread		
50	M10	1,00
25	M12	1,50
20	M14	1,50
10	M16	1,50

DISCOUNTS


Qty	1+	2+	5+
Disc. Prix	-5%		On request

Part N°	Quantity per box	Price each
BOX-NINA	550 washers	75,50 €

Our other products



PVL
Small lobed handle,
Polyamide

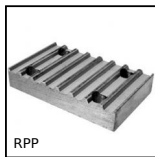

RRP
Connecting plate for
RPP type timing belts,
RRP5



PSG25
Spur gear - precision
range, Stainless steel
303



BLHT40
Right angled gearbox,
from 4 to 10.30 Nm



HG6
Steel spur gear, Steel
20NC2



GE
Toggle latches,
Miniature



HCSS
Set screw with
hexagonal socket,
Cup point



HRV
V-rail guidance
Simple Select®
system, Rail with
carriage



CDC
Conical compression
spring, Conical



T2
T type timing belt,
T2.5 Steel cored
polyurethane



WJUM10
Drylin® W bearing
block, Slide



SVG
Adjustable latch
clamp with strike
plate, Stroke with
82mm to 92mm

Complementary products



NIN
Self-locking nut, Steel



BOX-SHNA
Hexagonal nut -
DIN934, Box set of
steel nuts



BOX-WM
Box set of washer -
DIN125, Box set of
steel washers