

Box set of Nitrile O-rings

BOX-TOR-A Diameters from 2.9x1.78mm to 28.17x3.53mm



- Assortment conforming to AS/BS standard
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

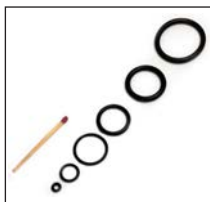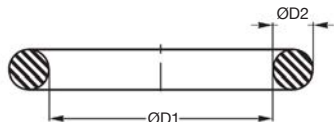

Box contents

| Quantity | ØD1 | ØD2 | Quantity | ØD1 | ØD2 | Quantity | ØD1 | ØD2 |
|----------|-------|------|----------|-------|------|----------|-------|------|
| 20 | 2,90 | 1,78 | 10 | 15,60 | 1,78 | 5 | 20,29 | 2,62 |
| 20 | 3,68 | 1,78 | 5 | 17,16 | 1,78 | 5 | 21,89 | 2,62 |
| 20 | 4,48 | 1,78 | 5 | 18,77 | 1,78 | 5 | 23,47 | 2,62 |
| 20 | 5,28 | 1,78 | 15 | 9,19 | 2,62 | 5 | 18,64 | 3,53 |
| 20 | 6,07 | 1,78 | 15 | 10,78 | 2,62 | 5 | 20,22 | 3,53 |
| 20 | 7,66 | 1,78 | 15 | 12,37 | 2,62 | 5 | 21,82 | 3,53 |
| 20 | 9,25 | 1,78 | 15 | 13,95 | 2,62 | 5 | 23,40 | 3,53 |
| 15 | 10,82 | 1,78 | 10 | 15,54 | 2,62 | 5 | 24,99 | 3,53 |
| 15 | 12,42 | 1,78 | 10 | 17,13 | 2,62 | 5 | 26,58 | 3,53 |
| 10 | 14,00 | 1,78 | 10 | 18,72 | 2,62 | 5 | 28,17 | 3,53 |

DISCOUNTS

| Qty | 1+ | 3+ | 5+ |
|-------|-----|-----|------------|
| Disc. | Net | -5% | On request |

| Part N° | Material | Quantity per box | Price each 1 to 2 |
|-----------|-------------|------------------|-------------------|
| BOX-TOR-A | NBR 70 Sh A | 340 o-rings | 56,21 € |

All dimensions in mm

Our other products



GCH

Linear ball slide -
Stainless steel balls,
Chariot - from 514 N
to 1...



PTA40

Articulated foot with
solid base foot \varnothing 40,
30000N




PSG05HC

Skive hobbed spur
gears - precision
range, Case hardened
steel 20NCD2



GLB

Small 6 lobe female
handle,
Technopolymer -
Stainless steel

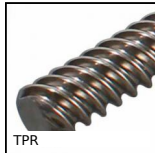

TPR

High helix leadscrew,
Leadscrew only - up
to 40mm per rotation



GLB

Small 6 lobe female
handle,
Technopolymer -
Brass



PW_PWG1

Wheel - precision
range, Bronze



PRF-SRA-78

Lock for aluminium
profile, Quick fitting,
self locking door lock



HLC19

Right angle spiro
bevel gearbox, Up to
1000W



CHA_GC_9SS

Stainless steel garnet
hinge, To be welded



Q1

Self-aligning radial
ball bearing, Steel



CQA20

Adjustment slide-
system miniature, 20

Complementary products



BOX-TOR-TOOL

Box set of tool for
Nitrile O-rings,
Extraction tools