

Box set of Nitrile O-rings

BOX-TOR-A Diameters from 2.9x1.78mm to 28.17x3.53mm



- Assortment conforming to AS/BS standard
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

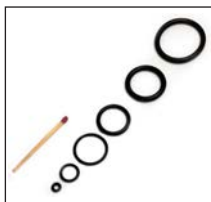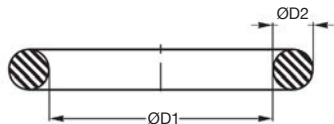

Box contents

Quantity	ØD1	ØD2
20	2,90	1,78
20	3,68	1,78
20	4,48	1,78
20	5,28	1,78
20	6,07	1,78
20	7,66	1,78
20	9,25	1,78
15	10,82	1,78
15	12,42	1,78
10	14,00	1,78

Quantity	ØD1	ØD2
10	15,60	1,78
5	17,16	1,78
5	18,77	1,78
15	9,19	2,62
15	10,78	2,62
15	12,37	2,62
15	13,95	2,62
10	15,54	2,62
10	17,13	2,62
10	18,72	2,62

Quantity	ØD1	ØD2
5	20,29	2,62
5	21,89	2,62
5	23,47	2,62
5	18,64	3,53
5	20,22	3,53
5	21,82	3,53
5	23,40	3,53
5	24,99	3,53
5	26,58	3,53
5	28,17	3,53

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-A	NBR 70 Sh A	340 o-rings	56,21 €

 
All dimensions in mm

Our other products



RAS

90° ball and socket joints DIN71802, Steel



PRF-SCREEN-1

Screen support, Basic support



BSP

Compact precision slide, from 156 N to 980 N



KGS

Ballscrew, supplied by the metre, Rolled ballscrew, per metre



DER71

Stainless steel AC asynchronous motor 0.25 à 0.37kW, 0.25 to 0.37kW



DOMI120

Accessories, Fixing kit



RAM35

Manual bevel gearbox, Bevel



VB

Small 6 lobe threaded handle - female, Duroplast - Stainless steel



IBJ

180° ball and socket joints, Steel



GAL48_OMNI

Omni-directional roller, Omni-directional



PM4

Worm and wheel set, Bronze



PRF-SCREEN-4

Screen support, Support with 4 axes of rotation

Complementary products



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools