

Box set of Nitrile O-rings

BOX-TOR-A Diameters from 2.9x1.78mm to 28.17x3.53mm



- Assortment conforming to AS/BS standard
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

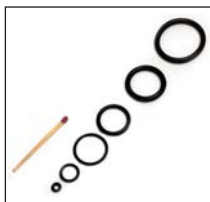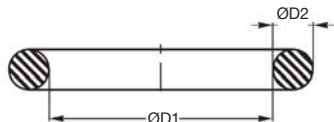

Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	2,90	1,78	10	15,60	1,78	5	20,29	2,62
20	3,68	1,78	5	17,16	1,78	5	21,89	2,62
20	4,48	1,78	5	18,77	1,78	5	23,47	2,62
20	5,28	1,78	15	9,19	2,62	5	18,64	3,53
20	6,07	1,78	15	10,78	2,62	5	20,22	3,53
20	7,66	1,78	15	12,37	2,62	5	21,82	3,53
20	9,25	1,78	15	13,95	2,62	5	23,40	3,53
15	10,82	1,78	10	15,54	2,62	5	24,99	3,53
15	12,42	1,78	10	17,13	2,62	5	26,58	3,53
10	14,00	1,78	10	18,72	2,62	5	28,17	3,53

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-A	NBR 70 Sh A	340 o-rings	56,21 €

All dimensions in mm

Our other products



BPLE
Ball transfer unit push fit, Light



AT5-BAR
AT type tooth bar stock, AT5



RFK48B
Hypoid gearbox -
Stainless steel, up to
350 Nm



TCSH
Automatic chain
tensioner, With
support



SHA_PTR
Handwheel with
folding handle,
Polyamide




RAGFLOW
Floway2® roller track,
Roller track



DCG
Suction cup, 2.5
bellows, nitrile



 AT5-16ECO
AT type timing pulley,
Economy range - AT5
aluminium



SLHHlok
Horizontal toggle
clamp, Horizontal



ACAss
Stainless steel splined
shaft, Stainless steel



PCLA_M
Technopolymer
clamping lever -



DIV
Locking bolt, With grip
- Steel

Complementary products



BOX-TOR-TOOL
Box set of tool for
Nitrile O-rings,
Extraction tools