

Box set of Nitrile O-rings

BOX-TOR-A Diameters from 2.9x1.78mm to 28.17x3.53mm



- Assortment conforming to AS/BS standard
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

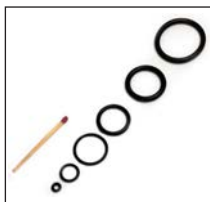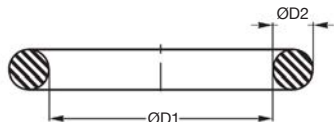

Box contents

Quantity	ØD1	ØD2
20	2,90	1,78
20	3,68	1,78
20	4,48	1,78
20	5,28	1,78
20	6,07	1,78
20	7,66	1,78
20	9,25	1,78
15	10,82	1,78
15	12,42	1,78
10	14,00	1,78

Quantity	ØD1	ØD2
10	15,60	1,78
5	17,16	1,78
5	18,77	1,78
15	9,19	2,62
15	10,78	2,62
15	12,37	2,62
15	13,95	2,62
10	15,54	2,62
10	17,13	2,62
10	18,72	2,62

Quantity	ØD1	ØD2
5	20,29	2,62
5	21,89	2,62
5	23,47	2,62
5	18,64	3,53
5	20,22	3,53
5	21,82	3,53
5	23,40	3,53
5	24,99	3,53
5	26,58	3,53
5	28,17	3,53


DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-A	NBR 70 Sh A	340 o-rings	56,21 €

All dimensions in mm

 Our other products



RPPM
RPP type belt per
metre, RPP5 Steel
cored polyurethane



BG
Oldham coupling,
With set screw



SUPTOOL
Installation tools for
clamping hub, For
hexagonal clamping
hub



MFB_MHB
Moulded plastic bevel
gear (nylon), 4:1



AT5courroie
AT type timing belt,
AT5 Steel cored
polyurethane



BSCf
Knurled torque knobs
- female, Knurled
threaded torque



TFR
Rigid manual
tensioner, Fixed



CHMBR
Reaction arm, CHM
and CHMR gear
reducers reaction arm



DOMI120
Domino 120
adjustable slide, Slide
DOMILINE 120 with



KSM
Cylindrical steel nut,
Steel - 1 thread



VLBS
Folding lifting ring for
welding, Folding - for
welding



H0
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2

Complementary products



BOX-TOR-TOOL
Box set of tool for
Nitrile O-rings,
Extraction tools