

Box set of Nitrile O-rings

Diameters 20,38x1,78mm to 50,16x5,34mm **BOX-TOR-B**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

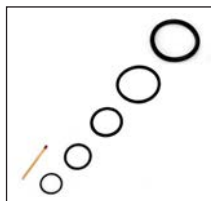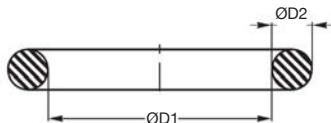

Box contents

Quantity	ØD1	ØD2
15	20,35	1,78
15	21,95	1,78
15	25,07	2,62
15	26,64	2,62
15	28,25	2,62
15	29,82	2,62
10	31,42	2,62
10	33,00	2,62
10	34,59	2,62
15	29,75	3,53
15	31,34	3,53
15	32,92	3,53

Quantity	ØD1	ØD2
10	34,52	3,53
10	36,10	3,53
10	37,69	3,53
10	40,87	3,53
10	44,04	3,53
10	47,22	5,53
10	50,40	3,53
10	37,47	5,34
10	40,65	5,34
10	43,82	5,34
5	47,00	5,34
5	50,16	5,34

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-B	NBR 70 Sh A	275 o-rings	104,60 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

213

Our other products



FBL6000_K13
Brush strip per meter
PP fibres Ø0.2, Black
striated polypropylene
...



RDS
Safety washer
Hygienic Usit®,
Stainless steel



PARF110
Pressed steel base
rigid foot, Swivelling
Ø110



ABL100000
Antistatic brush, For
sensitive surfaces



CHML40
Worm and wheel gear
reducer, up to 57 Nm
- Integrated torque
limiter



RCC_RCX
Spherical tilt washer -
DIN6319, concave



MAX22
Motor-gearbox 12V
and 24V DC, from
0,07 to 0,2Nm



DER71
Stainless steel AC
asynchronous motor
0.25 à 0.37kW, 0.25
to 0.37kW



CHT
Asynchronous AC
Motor, 0.18 to 0.55kW



AT5-16ECO
AT type timing pulley,
Economy range - AT5
aluminium



FF40
Offset spur gear
reducer, from 59 to
210 Nm



HRV
V- rail guidance
Simple Select®
system, Rail with
carriage

Complementary products



BOX-TOR-TOOL
Box set of tool for
Nitrile O-rings,
Extraction tools