

Box set of Nitrile O-rings

Diameters 20,38x1,78mm to 50,16x5,34mm **BOX-TOR-B**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

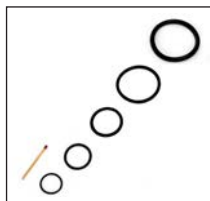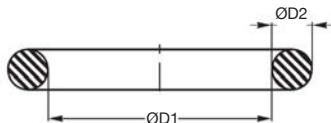

Box contents

Quantity	ØD1	ØD2
15	20,35	1,78
15	21,95	1,78
15	25,07	2,62
15	26,64	2,62
15	28,25	2,62
15	29,82	2,62
10	31,42	2,62
10	33,00	2,62
10	34,59	2,62
15	29,75	3,53
15	31,34	3,53
15	32,92	3,53

Quantity	ØD1	ØD2
10	34,52	3,53
10	36,10	3,53
10	37,69	3,53
10	40,87	3,53
10	44,04	3,53
10	47,22	5,53
10	50,40	3,53
10	37,47	5,34
10	40,65	5,34
10	43,82	5,34
5	47,00	5,34
5	50,16	5,34

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-B	NBR 70 Sh A	275 o-rings	104,60 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

213

Our other products



CPAS

Stay with safety catch, Opens upward



GET-AL

Jaw coupling, economy range, Aluminium



GCA

Linch pin, Linch



DB

Steel bevel gear, 2:1



HSSss

Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379



AK

Bellows coupling Gerwah®, from 36 to 800Nm



LRR

Catch-plate for latch, Catch-plate



 
BAG-MI

Split shaft collar with clamp lever, Steel



BOX-TOR-MAX

Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 82.14 x 3.53



PM3

Worm and wheel set, Machined plastic (delrin)



BDPR

Holding arm, Rigid



SVG

Adjustable latch clamp with strike plate, Stroke from 82mm to 92mm

Complementary products



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools