

Box set of Nitrile O-rings

Diameters 20,38x1,78mm to 50,16x5,34mm **BOX-TOR-B**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

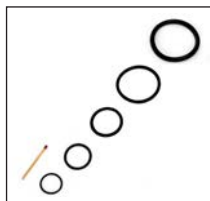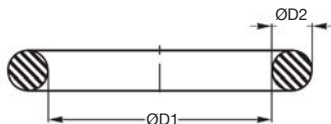

Box contents

Quantity	ØD1	ØD2
15	20,35	1,78
15	21,95	1,78
15	25,07	2,62
15	26,64	2,62
15	28,25	2,62
15	29,82	2,62
10	31,42	2,62
10	33,00	2,62
10	34,59	2,62
15	29,75	3,53
15	31,34	3,53
15	32,92	3,53

Quantity	ØD1	ØD2
10	34,52	3,53
10	36,10	3,53
10	37,69	3,53
10	40,87	3,53
10	44,04	3,53
10	47,22	5,53
10	50,40	3,53
10	37,47	5,34
10	40,65	5,34
10	43,82	5,34
5	47,00	5,34
5	50,16	5,34

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-B	NBR 70 Sh A	275 o-rings	104,60 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC


SUPPLEMENT 2019

213

Our other products



PPG
Indexing plunger with flange, With horizontal mounting flange

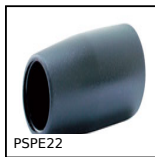

PSPE22
Conical flexible shaft handlee Ø22, Black PVC



G0
Steel spur gear, Steel 20NCD2



AT5P_AT10P
Connecting plate for AT type timing belts, AT10



BIMSS
Indexing plunger mini, miniature - Stainless steel



CHA38_SS
Stainless steel face frame hinge, Surface mount




M
Bellows cover, Accessory:



CLG2
Moulded plastic spur gear, Moulded plastic (nylon)



 MDB_MTB
Moulded plastic bevel gear (nylon), 2:1



LAT2
2A motorised linear actuator, 2 amperes



PSG125
Spur gear - precision range, Case hardened



PRF_GAL
Roller for aluminium profile, Flat roller

Complementary products



BOX-TOR-TOOL
Box set of tool for Nitrile O-rings, Extraction tools