

Box set of Nitrile O-rings

BOX-TOR-C Diameters 3,00x1,50mm à 30,20x3,00mm



- Box set of Nitrile O-rings
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

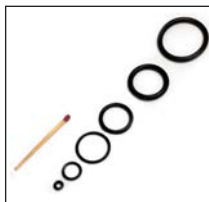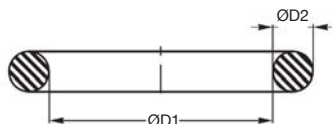

Box contents

Quantity	ØD1	ØD2
20	3,00	1,50
20	5,00	1,50
20	7,00	1,50
20	9,00	1,50
20	11,00	1,50
20	6,00	2,00
20	8,00	2,00
20	10,00	2,00
20	12,00	2,00
20	14,00	2,00

Quantity	ØD1	ØD2
15	6,30	2,40
15	8,30	2,40
15	11,30	2,40
15	13,30	2,40
15	17,30	2,40
15	5,00	2,50
15	7,00	2,50
15	10,00	2,50
15	12,00	2,50
15	15,00	2,50

Quantity	ØD1	ØD2
10	10,00	3,00
10	12,00	3,00
10	14,00	3,00
10	16,00	3,00
10	18,00	3,00
5	20,20	3,00
5	22,20	3,00
5	24,20	3,00
5	26,20	3,00
5	30,20	3,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-C	NBR 70 Sh A	425 o-rings	61,33 €

All dimensions in mm

Our other products



FBL6000_K1

Brush strip per meter
PA6 fibres Ø0.2 to
Ø0.3, Black polyamide
6 -...




TS01_TW01

Drylin® T linear slide,
up to 7000 N



ZBconique

Machined plastic
bevel gear, 1:1

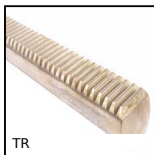

TR

Spur round rack,
Stainless steel -
module 0,25-1,5



VPRA_M

Handwheel with
handle,
Thermosetting plastic
- stainless steel hub



TOL

Swivel head, Long



RNAST

Cam follower without
axial guide, Without
interior ring



SVG

Adjustable latch
clamp with strike
plate, Stroke from
106,7mm to 121...



BAB

Hardened Stainless
steel ball pin,
threaded...



MSP3815

Masterplate®
glueable insert



LVT

Miniature motorised
actuator 2A, 2 amperes



GE

Toggle latches,
Standard

Complementary products

threaded...



BOX-TOR-TOOL

Box set of tool for
Nitrile O-rings,
Extraction tools