

Box set of Nitrile O-rings

BOX-TOR-C Diameters 3,00x1,50mm à 30,20x3,00mm



- Box set of Nitrile O-rings
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

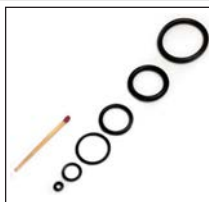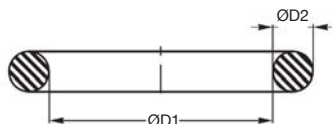

Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	3,00	1,50	15	6,30	2,40	10	10,00	3,00
20	5,00	1,50	15	8,30	2,40	10	12,00	3,00
20	7,00	1,50	15	11,30	2,40	10	14,00	3,00
20	9,00	1,50	15	13,30	2,40	10	16,00	3,00
20	11,00	1,50	15	17,30	2,40	10	18,00	3,00
20	6,00	2,00	15	5,00	2,50	5	20,20	3,00
20	8,00	2,00	15	7,00	2,50	5	22,20	3,00
20	10,00	2,00	15	10,00	2,50	5	24,20	3,00
20	12,00	2,00	15	12,00	2,50	5	26,20	3,00
20	14,00	2,00	15	15,00	2,50	5	30,20	3,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-C	NBR 70 Sh A	425 o-rings	61,33 €

All dimensions in mm

Our other products




PGM52-M4
Pull handle, Brass



FTSN
Supported shaft for linear guide, Steel shaft / Aluminium support



TBEBASE
Base plate for economic mini-table, Allows X-Y cross tables

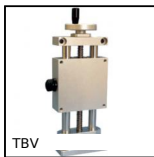

TBV
Manual lifting tables, 20kg



SHWbr
Washer - DIN125, Brass



ZBconique
Machined plastic bevel gear, 1:1



MET
Cylindrical sintered bronze bush, Self-lubricating sintered bronze



 
SUPTOOL
Installation tools for clamping hub, For hexagonal clamping hub



CHTRP
Single and dual output gearboxes, Up to 87,3Nm



PRF_ER
Joining bar for aluminium profile, Joint bar



RPP14
RPP heavy duty timing belt, RPP14



BS3
Panamech, Multi-Beam stainless steel, Stainless steel - with set screw

Complementary products



BOX-TOR-TOOL
Box set of tool for Nitrile O-rings, Extraction tools