

Box set of Nitrile O-rings

BOX-TOR-C Diameters 3,00x1,50mm à 30,20x3,00mm



- Box set of Nitrile O-rings
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

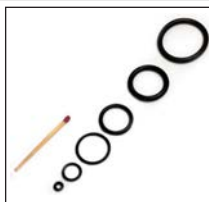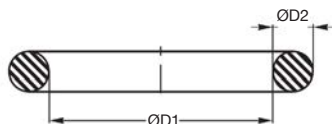

Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	3,00	1,50	15	6,30	2,40	10	10,00	3,00
20	5,00	1,50	15	8,30	2,40	10	12,00	3,00
20	7,00	1,50	15	11,30	2,40	10	14,00	3,00
20	9,00	1,50	15	13,30	2,40	10	16,00	3,00
20	11,00	1,50	15	17,30	2,40	10	18,00	3,00
20	6,00	2,00	15	5,00	2,50	5	20,20	3,00
20	8,00	2,00	15	7,00	2,50	5	22,20	3,00
20	10,00	2,00	15	10,00	2,50	5	24,20	3,00
20	12,00	2,00	15	12,00	2,50	5	26,20	3,00
20	14,00	2,00	15	15,00	2,50	5	30,20	3,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-C	NBR 70 Sh A	425 o-rings	61,33 €

All dimensions in mm

Our other products



Q6

Deep groove ball bearing, Steel



G4

Steel spur gear, Steel 20NCD2



ZBconique

Machined plastic bevel gear, 1:1



BSM_LOK

Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...




SVT30

Screwjack with travelling screw, with translating screw



ES

 Simple support base (bipod), Plastic



LWH

High rigidity linear slide, Chariot - from 9320 N to 71300 N



FIRSTDC1Q60

Speed controller 10A, 10 A



SKM

Hexagonal steel nut, Steel - 1 thread



ZG4

Plastic spur gear, Machined plastic (delrin)



RVM25

Manually operated gearbox, Bevel



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane

Complementary products



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools