

# Box set of Nitrile O-rings

## BOX-TOR-C Diameters 3,00x1,50mm à 30,20x3,00mm

- Box set of Nitrile O-rings
- 30 different sizes
- Material:  
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



### Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

### Info

- Ideal for the maintenance department

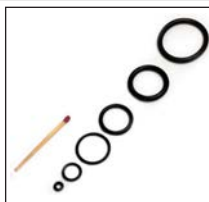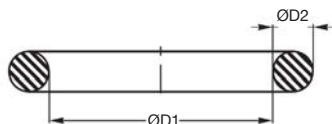

### Box contents

Quantity	ØD1	ØD2
20	3,00	1,50
20	5,00	1,50
20	7,00	1,50
20	9,00	1,50
20	11,00	1,50
20	6,00	2,00
20	8,00	2,00
20	10,00	2,00
20	12,00	2,00
20	14,00	2,00

Quantity	ØD1	ØD2
15	6,30	2,40
15	8,30	2,40
15	11,30	2,40
15	13,30	2,40
15	17,30	2,40
15	5,00	2,50
15	7,00	2,50
15	10,00	2,50
15	12,00	2,50
15	15,00	2,50

Quantity	ØD1	ØD2
10	10,00	3,00
10	12,00	3,00
10	14,00	3,00
10	16,00	3,00
10	18,00	3,00
5	20,20	3,00
5	22,20	3,00
5	24,20	3,00
5	26,20	3,00
5	30,20	3,00

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-C	NBR 70 Sh A	425 o-rings	61,33 €

All dimensions in mm

## Our other products



LRX

Linear roller slide,  
Chariot - from 9410 N  
to 101000 N



BG

Oldham coupling,  
With set screw



CFURSS

Cam follower stainless  
steel, Standard -  
stainless steel



ZBconique

Machined plastic  
bevel gear , 1:1



BAP

Plastic clamping  
collar, Ø10 - Ø20



PSPT

Flexible tube handle,  
PVC



NIN

Self-locking nut, A2  
Stainless steel



DPAR\_DKON

Progressive stop,  
Steel



DGSA

Male rod ends , Steel /  
steel - Economy range



HRV

V- rail guidance  
Simple Select®  
system, Rail with



VT

Vari-Tork® slip  
friction clutch, 0.53 to  
1.32 Nm



RPP

Connecting plate for  
RPP type timing belts,  
RPP8

## Complementary products



BOX-TOR-TOOL

Box set of tool for  
Nitrile O-rings,  
Extraction tools