

# Box set of Nitrile O-rings

## BOX-TOR-C Diameters 3,00x1,50mm à 30,20x3,00mm



- Box set of Nitrile O-rings
- 30 different sizes
- Material:  
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

### Uses

- Suitable for:
- Hydraulic oils
  - HFA fluids
  - HFB fluids
  - HFC fluids
  - Air

### Info

- Ideal for the maintenance department

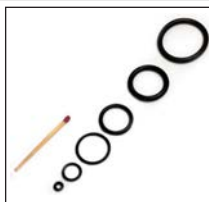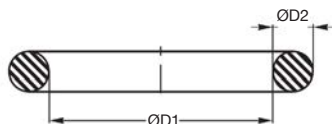

### Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	3,00	1,50	15	6,30	2,40	10	10,00	3,00
20	5,00	1,50	15	8,30	2,40	10	12,00	3,00
20	7,00	1,50	15	11,30	2,40	10	14,00	3,00
20	9,00	1,50	15	13,30	2,40	10	16,00	3,00
20	11,00	1,50	15	17,30	2,40	10	18,00	3,00
20	6,00	2,00	15	5,00	2,50	5	20,20	3,00
20	8,00	2,00	15	7,00	2,50	5	22,20	3,00
20	10,00	2,00	15	10,00	2,50	5	24,20	3,00
20	12,00	2,00	15	12,00	2,50	5	26,20	3,00
20	14,00	2,00	15	15,00	2,50	5	30,20	3,00

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-C	NBR 70 Sh A	425 o-rings	61,33 €

All dimensions in mm

## Our other products



NCT  
Square tube  
connector, Fixed  
angle



LRRss  
Latch, Spring loaded  
latch - stainless steel




PRT-TO  
igidur® slewing ring,  
With external teeth-  
Iglidur®, aluminium &  
S...



PVL  
Small lobed handle,  
Polyamide



 PR125  
Articulated foot Ø123,  
Ø 123



RPPM  
RPP type belt per  
metre, RPP8 Steel  
cored polyurethane



HTD8M\_20  
HTD Heavy duty  
timing pulley, HTD8  
Steel



PFM  
Fixed levelling foot,  
Flanged plate



LBE  
Miniature closed  
linear bearing,  
Miniature



DZY  
Cylindrical stop, Steel



BAC110  
Swivel storage bin,  
Storage bin



RT25  
Self-centering flanged  
locking assembly,  
Medium/high torque

## Complementary products



BOX-TOR-TOOL  
Box set of tool for  
Nitrile O-rings,  
Extraction tools