

Box set of Nitrile O-rings

Diameters 18,00x2,00mm à 50,00x5,00mm **BOX-TOR-D**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

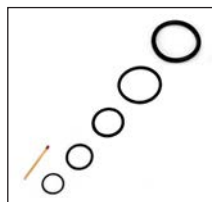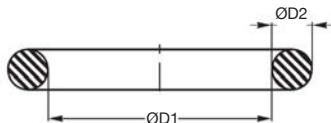

Box contents

Quantity	ØD1	ØD2
15	18,00	2,00
15	20,00	2,00
15	22,00	2,00
15	25,00	2,00
15	28,20	3,00
15	30,20	3,00
10	32,20	3,00
10	26,20	3,00
15	25,00	4,00
15	30,00	4,00
15	32,00	4,00
15	34,00	4,00

Quantity	ØD1	ØD2
15	36,00	4,00
10	38,00	4,00
10	10,00	4,00
10	44,00	4,00
10	48,00	4,00
10	50,00	4,00
10	25,00	5,00
10	30,00	5,00
10	35,00	5,00
10	40,00	5,00
5	45,00	5,00
5	50,00	5,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-D	NBR 70 Sh A	285 o-rings	106,37 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

Our other products



MC
Self-compensating shock-absorber, Self-compensating - without adjust...



F7-I
Multifunction display, With internal sensor




CHM110
Worm and wheel gear reducer, up to 980 Nm



SVR30
Screwjack with travelling nut, with moving nut



 CHB
Reaction arm, CHB gear reducers reaction arm




M0
Worm and wheel set, Machined plastic (delrin)



RESC
Retractable castor for aluminium profile, Retractable castor



 
ACL
Joints for aluminium profile, Variable angle hinge



RPP
Connecting plate for RPP type timing belts, ...



 PTCR
Adjustable furniture foot, square tube



PRF-GUM
Aluminium profile anodising polisher, ...



CHAsb63
Hinge without pin, Polymer pin hinge

Complementary products



BOX-TOR-TOOL
Box set of tool for Nitrile O-rings, Extraction tools