

Box set of Nitrile O-rings

Diameters 18,00x2,00mm à 50,00x5,00mm **BOX-TOR-D**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

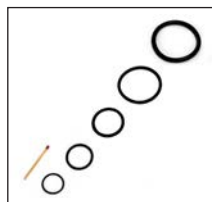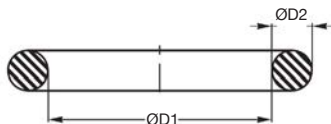

Box contents

Quantity	ØD1	ØD2
15	18,00	2,00
15	20,00	2,00
15	22,00	2,00
15	25,00	2,00
15	28,20	3,00
15	30,20	3,00
10	32,20	3,00
10	26,20	3,00
15	25,00	4,00
15	30,00	4,00
15	32,00	4,00
15	34,00	4,00

Quantity	ØD1	ØD2
15	36,00	4,00
10	38,00	4,00
10	10,00	4,00
10	44,00	4,00
10	48,00	4,00
10	50,00	4,00
10	25,00	5,00
10	30,00	5,00
10	35,00	5,00
10	40,00	5,00
5	45,00	5,00
5	50,00	5,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-D	NBR 70 Sh A	285 o-rings	106,37 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

Our other products



ACL-PR
Joining plate for aluminium profile, Right angled connection



DER80
Stainless steel AC asynchronous motor 0.55 - 0.75kW, 0.55 to 0.75kW




PTA100
Articulated levelling foot, pressed base Ø100, Ø 100



DOMI80
Domino 80 adjustable slide, Slide DOMILINE 80



 ACM_AZ
Mounting bracket for bonnet fastener, Hook



M1
Worm and wheel set, Bronze




PTAF80-PAMF80
Articulated fixable foot with pressed base Ø80, Ø 80



PLN
Cylindrical spacer, Thermoplastic



 CHASb89
Hinge without pin, Plastic hinge



RPPM
RPP type belt metre, RPP5 Steel



T5P_T10P
Connecting plate for T type timing belts, T5



CHALss
Piano hinge, Stainless steel

Complementary products



BOX-TOR-TOOL
Box set of tool for Nitrile O-rings, Extraction tools