

D-Ring Kit, NBR Shore A

Flange seals

BOX-TOR-DRING

- Selection of D-Ring flange seals
- 9 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

Applications


- Suitable for:
- Hydraulic fluids
 - HFA fluids
 - HFB fluids
 - HFC fluids

Advantages

- Good extrusion resistance
- Long service life
- Easy to assemble as the seal will adhere to the flange
- Good resistance to vibration and low temperatures


Info

- Ideal for use in the maintenance dept

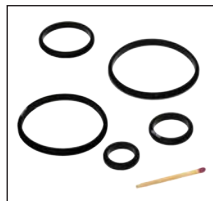

Box contents

Quantity	ØA	B	H
10	18,90	3,40	4,95
10	25,25	3,40	4,95
10	31,60	3,40	4,95
10	37,95	3,40	4,95
10	44,37	3,40	4,95
10	50,72	3,40	4,95
10	54,20	3,40	4,95
5	57,07	3,40	4,95
5	63,42	3,40	4,95

 

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-DRING	NBR 90 Sh A	80 pieces	202,15 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

221

Our other products



PTA80

Articulated levelling foot, pressed base Ø80, Ø 80



CHM63-MOT

Asynchronous AC motorgearboxes 0.37 to 1.5kW, 0.37 to 1.5kW



GD01

Double universal joint, Standard duty



BCM_CC

Modular cylindrical brush, Horsehair bristles



PDD

Actuating plunger, Non-rotating detector shaft



PR105

Articulated foot Ø103, Ø 103



CHTRP

Single and dual output gearboxes, Up to 28,8 Nm



BIM

Indexing plunger mini, miniature



 
WING

Manually tightened wing nut, Steel (ANSI)



CABPVC

PVC covered galvanised steel



G0

Steel spur gear, Steel 20NCD2



PW_PWG3

Worm - precision range, Stainless steel

Complementary products

transparen...



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools