

D-Ring Kit, NBR Shore A

Flange seals

BOX-TOR-DRING

- Selection of D-Ring flange seals
- 9 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

Applications


- Suitable for:
- Hydraulic fluids
 - HFA fluids
 - HFB fluids
 - HFC fluids

Advantages

- Good extrusion resistance
- Long service life
- Easy to assemble as the seal will adhere to the flange
- Good resistance to vibration and low temperatures


Info

- Ideal for use in the maintenance dept

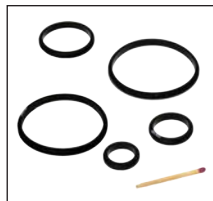

Box contents

Quantity	ØA	B	H
10	18,90	3,40	4,95
10	25,25	3,40	4,95
10	31,60	3,40	4,95
10	37,95	3,40	4,95
10	44,37	3,40	4,95
10	50,72	3,40	4,95
10	54,20	3,40	4,95
5	57,07	3,40	4,95
5	63,42	3,40	4,95

 

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-DRING	NBR 90 Sh A	80 pieces	202,15 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

221

Our other products



AKD

Bellows coupling
Gerwah®, from 22 to
600Nm



PM2

Worm and wheel set,
Bronze



RPP

Connecting plate for
RPP type timing belts,
RPP8



CHMX_CHMDX

Shaft for worm and
wheel reducer CHMR
and CHM, CHMR and
CHM gearbox...



KITdog

24V DC motorisation
kit, Worm and wheel



BABreglable

Adjustable ball pin
hardened stainless
steel, adjustable



PSG3

Spur gear - precision
range, Pre-hardened
Steel 35NCD6



HSE-HSB

Hexagonal spacer,
Steel



DOMI120

Accessories, Clamping
lever



BPLE

Ball transfer unit push
fit, Light



BOX-TOR-D

Box set of Nitrile O-
rings in nitrile, 18.00 x



R204

Die spring ISO10243,
Average

Complementary products



BOX-TOR-TOOL

Box set of tool for
Nitrile O-rings,
Extraction tools