

D-Ring Kit, NBR Shore A

Flange seals

BOX-TOR-DRING

- Selection of D-Ring flange seals
- 9 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

Applications


- Suitable for:
- Hydraulic fluids
 - HFA fluids
 - HFB fluids
 - HFC fluids

Advantages

- Good extrusion resistance
- Long service life
- Easy to assemble as the seal will adhere to the flange
- Good resistance to vibration and low temperatures


Info

- Ideal for use in the maintenance dept

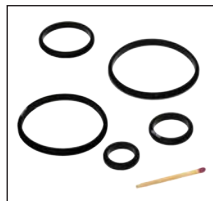

Box contents

Quantity	ØA	B	H
10	18,90	3,40	4,95
10	25,25	3,40	4,95
10	31,60	3,40	4,95
10	37,95	3,40	4,95
10	44,37	3,40	4,95
10	50,72	3,40	4,95
10	54,20	3,40	4,95
5	57,07	3,40	4,95
5	63,42	3,40	4,95

 

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-DRING	NBR 90 Sh A	80 pieces	202,15 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax


cial2@hpceurope.com

HPC

SUPPLEMENT 2019

221

 Our other products



PO

Pull handle - Multi-sector, Smooth hole



RPCpl

Swivel castor with plate, Steel - Polyamide




LRR-53

Spring loaded latch, Spring return latch - steel



PRF_BR

Clamp for aluminium profile, Clamp for profile

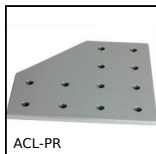

ACL-PR

Joining plate for aluminium profile, Right angled connection



NT61

Spur gear coaxial gearbox, from 5 to 14 Nm - Inline



DB

Steel bevel gear, 2:1



PLM-C

Flat gripping magnet, Flat holding magnet



DCG

Suction cup, 2.5 bellows, silicon



HBM

Adjustment bushing for half-rail guide,



RT70

Self-centering locking Assembly,



DZY

Cylindrical stop, Steel

Complementary products



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools