

# Box set of Nitrile O-rings

## BOX-TOR-G Diameters 3,00x1,50mm à 30,20x3,00mm


- Box set of Nitrile O-rings
- 30 different sizes
- Material:  
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

### Uses

- Suitable for:
- Hydraulic oils
  - HFA fluids
  - HFB fluids
  - HFC fluids
  - Air

### Info

- Ideal for the maintenance department

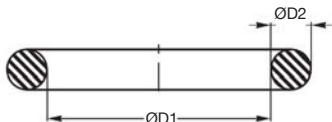

### Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	2,90	1,78	13	13,95	2,62	10	28,17	3,53
20	3,68	1,78	13	15,54	2,62	10	29,75	3,53
20	4,48	1,78	13	17,13	2,62	10	31,34	3,53
20	5,28	1,78	13	18,72	2,62	10	32,92	3,53
20	6,07	1,78	13	18,64	3,53	10	34,52	3,53
20	7,66	1,78	10	20,22	3,53	10	36,10	3,53
20	9,25	1,78	10	21,82	3,53	10	37,69	3,53
13	9,19	2,62	10	23,40	3,53	7	37,47	5,34
13	10,78	2,62	10	24,99	3,53	7	40,65	5,34
13	12,37	2,62	10	26,58	3,53	7	43,82	5,34

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Stock*	Price each 1 to 2
BOX-TOR-G	NBR 70 Sh A	382 o-rings	✓	28,92 €

All dimensions in mm

## Our other products



PAM\_SS  
Stainless steel articulated levelling foot, Ø 30 & 40



T10\_21\_AL  
T type timing pulley, Economy range - T10 aluminium



G1  
Steel spur gear, Steel 20NCD2



RLX  
Free running conveyor roller, PVC



RDE-W  
Sealing washer Hygienic Usit®, Stainless steel - White EPDM



UTKswrr  
V shaped channel UtiliTrak®, V rail



TMR  
Rigid manual tensioner, Adjustable



DEP  
Tools Hygienic Usit® and Hygienic Design®, Socket for mounting Hyg...



H0  
Crossed helical gear crossed axis at 90°, stainless steel



DOMI80  
Connecting kits, XY linking kit



MSP3815  
Masterplate® glueable insert



M0  
Worm and wheel set, Non hardened steel

## Complementary products

threaded...



BOX-TOR-TOOL  
Box set of tool for Nitrile O-rings, Extraction tools