

Box set of Nitrile O-rings

BOX-TOR-G Diameters 3,00x1,50mm à 30,20x3,00mm


- Box set of Nitrile O-rings
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

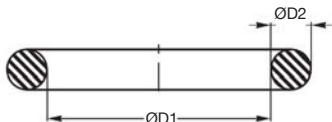

Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	2,90	1,78	13	13,95	2,62	10	28,17	3,53
20	3,68	1,78	13	15,54	2,62	10	29,75	3,53
20	4,48	1,78	13	17,13	2,62	10	31,34	3,53
20	5,28	1,78	13	18,72	2,62	10	32,92	3,53
20	6,07	1,78	13	18,64	3,53	10	34,52	3,53
20	7,66	1,78	10	20,22	3,53	10	36,10	3,53
20	9,25	1,78	10	21,82	3,53	10	37,69	3,53
13	9,19	2,62	10	23,40	3,53	7	37,47	5,34
13	10,78	2,62	10	24,99	3,53	7	40,65	5,34
13	12,37	2,62	10	26,58	3,53	7	43,82	5,34

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Stock*	Price each 1 to 2
BOX-TOR-G	NBR 70 Sh A	382 o-rings	✓	28,92 €

All dimensions in mm

Our other products



SUPss

Self-centering clamping hub stainless steel, Without locknut



PRFSRAD

Dual lock for aluminium profile, Quick fitting, self locking door du...



PRF_PF

Anchoring bracket for aluminium profile, Anchor



INS_SS

Self tapping stainless steel insert, 316 stainless steel



SERB

Cam latch, Cam latch



CHCSS

Socket headed screw, Stainless steel - A2



PSG3

Spur gear - precision range, Case hardened steel 20NCD2



NAST

Cam follower without axial guide, With interior ring



UCP_PBT

Stainless/Polymer pillow block bearing,




EX

Optional shaft for E-type gear reducers, E



RTE

Rotex®, jaw coupling, cast iron

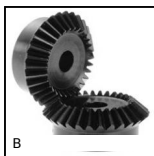

B

Steel bevel gear, 1:1

Complementary products



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools