

# Box set of Nitrile O-rings

## BOX-TOR-G Diameters 3,00x1,50mm à 30,20x3,00mm


- Box set of Nitrile O-rings
- 30 different sizes
- Material:  
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

### Uses

- Suitable for:
- Hydraulic oils
  - HFA fluids
  - HFB fluids
  - HFC fluids
  - Air

### Info

- Ideal for the maintenance department

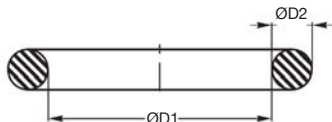

### Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	2,90	1,78	13	13,95	2,62	10	28,17	3,53
20	3,68	1,78	13	15,54	2,62	10	29,75	3,53
20	4,48	1,78	13	17,13	2,62	10	31,34	3,53
20	5,28	1,78	13	18,72	2,62	10	32,92	3,53
20	6,07	1,78	13	18,64	3,53	10	34,52	3,53
20	7,66	1,78	10	20,22	3,53	10	36,10	3,53
20	9,25	1,78	10	21,82	3,53	10	37,69	3,53
13	9,19	2,62	10	23,40	3,53	7	37,47	5,34
13	10,78	2,62	10	24,99	3,53	7	40,65	5,34
13	12,37	2,62	10	26,58	3,53	7	43,82	5,34

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Stock*	Price each 1 to 2
BOX-TOR-G	NBR 70 Sh A	382 o-rings	✓	28,92 €

All dimensions in mm

## Our other products



 
**FBL4004\_K7**  
Brush strip per meter  
PA6 fibres Ø0.3 to  
Ø0.5, Black polyamide  
6 -...



**BOX-TOR-TOOL**  
Box set of tool for  
Nitrile O-rings,  
Extraction tools




**CHAR**  
Spring hinge, screwed



**TPR**  
High helix leadscrew,  
Leadscrew only - up  
to 40mm per rotation



 **CHT**  
Asynchronous AC  
Motor 1.1 to 1.85kW,  
1.1 to 1.85kW



**CRM**  
Moulded nylon rack,  
Nylon



**CAP820**  
Slim slat top chain  
acetal, Narrow  
straight range 820



**CHM40**  
Worm and wheel gear  
reducer, up to 57 Nm



**CFUURSS**  
Cam follower stainless  
steel, Standard -



**ACLBDB**  
Closing mechanism  
for aluminium profile,



**CHAR16046**  
Spring hinge, screwed



**UTKswrr**  
V shaped channel  
UtiliTrak®, V rail

## Complementary products



**BOX-TOR-TOOL**  
Box set of tool for  
Nitrile O-rings,  
Extraction tools