

Box set of Nitrile O-rings

Diameters 3,00x2,00mm à 45,20x4,00mm **BOX-TOR-H**


- Box set of Nitrile O-rings
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

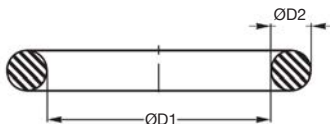

Box contents

Quantity	ØD1	ØD2
18	3,00	2,00
18	4,00	2,00
18	5,00	2,00
18	6,00	2,00
17	7,00	2,00
17	8,00	2,00
17	10,00	2,00
14	10,00	2,50
14	11,00	2,50
14	12,00	2,50

Quantity	ØD1	ØD2
14	14,00	2,50
14	16,00	2,50
14	17,00	2,50
14	19,00	2,50
12	19,00	3,00
12	20,00	3,00
12	22,00	3,00
12	24,00	3,00
12	25,00	3,00
12	27,00	3,00

Quantity	ØD1	ØD2
12	28,00	3,00
12	30,00	3,00
12	32,00	3,00
12	33,00	3,00
12	35,00	3,00
12	36,00	3,00
12	38,00	3,00
9	38,00	4,00
9	42,00	4,00
9	45,00	4,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Stock*	Price each 1 to 2
BOX-TOR-H	NBR 70 Sh A	404 o-rings	✓	27,73 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

Our other products



QN

Single row cylindrical roller bearing, Free outer ring



ACM_AZ

Mounting bracket for bonnet fastener, Hook



UTKpwc

Utilitrak® 3 wheels carriage, Polymer series V wheels



ASM

Cylindrical polymer bush, Food grade polymer



VTAP

Magnetic head screw, With rubber coating With rubber coating



PRF_GAL

Roller for aluminium profile, Fixing kit for roller concentric



YG1

HEAVY DUTY spur gear, Steel 35NCD6



T10courroie

T type timing belt, T10 Steel cored polyurethane



ADSR

Backlash free coupling Gerwah®,



SSDB

Stainless steel bevel gear, 2:1



CLM

Male clevis end, Stainless steel short



DB

Steel bevel gear, 2:1

Complementary products



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools