

Box set of Nitrile O-rings

Diameters 3,00x2,00mm à 45,20x4,00mm **BOX-TOR-H**


- Box set of Nitrile O-rings
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

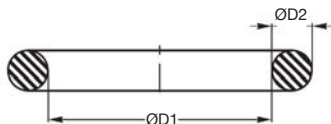

Box contents

Quantity	ØD1	ØD2
18	3,00	2,00
18	4,00	2,00
18	5,00	2,00
18	6,00	2,00
17	7,00	2,00
17	8,00	2,00
17	10,00	2,00
14	10,00	2,50
14	11,00	2,50
14	12,00	2,50

Quantity	ØD1	ØD2
14	14,00	2,50
14	16,00	2,50
14	17,00	2,50
14	19,00	2,50
12	19,00	3,00
12	20,00	3,00
12	22,00	3,00
12	24,00	3,00
12	25,00	3,00
12	27,00	3,00

Quantity	ØD1	ØD2
12	28,00	3,00
12	30,00	3,00
12	32,00	3,00
12	33,00	3,00
12	35,00	3,00
12	36,00	3,00
12	38,00	3,00
9	38,00	4,00
9	42,00	4,00
9	45,00	4,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Stock*	Price each 1 to 2
BOX-TOR-H	NBR 70 Sh A	404 o-rings	✓	27,73 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

Our other products



Single chain supplied by the metre, Steel



Internal epicyclic servo reducers, from 3.4 to 7 Nm



Spur gear - precision range, Case hardened steel 20NCD2



Horizontal hook toggle clamp, Horizontal Hook clamp - stainless steel



Accessory for adjustment slide-system, 20



 
Stainless steel diablo shaped elasto mount, Stainless steel



Ball transfer unit light duty, Light



Extension springs DIN2097, DIN 2097




Stainless steel metric section rack, Stainless



Bellows coupling Gerwah®, from 0.4 to



630 Stainless steel compact ball pin,

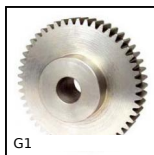

Steel spur gear, Steel 20NCD2

Complementary products



Box set of tool for Nitrile O-rings, Extraction tools