

# Box set of Nitrile O-rings

Diameters 3,00x2,00mm à 45,20x4,00mm **BOX-TOR-H**


- Box set of Nitrile O-rings
- 30 different sizes
- Material:  
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

## Uses

- Suitable for:
- Hydraulic oils
  - HFA fluids
  - HFB fluids
  - HFC fluids
  - Air

## Info

- Ideal for the maintenance department

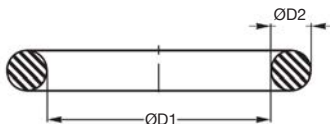

## Box contents

Quantity	ØD1	ØD2
18	3,00	2,00
18	4,00	2,00
18	5,00	2,00
18	6,00	2,00
17	7,00	2,00
17	8,00	2,00
17	10,00	2,00
14	10,00	2,50
14	11,00	2,50
14	12,00	2,50

Quantity	ØD1	ØD2
14	14,00	2,50
14	16,00	2,50
14	17,00	2,50
14	19,00	2,50
12	19,00	3,00
12	20,00	3,00
12	22,00	3,00
12	24,00	3,00
12	25,00	3,00
12	27,00	3,00

Quantity	ØD1	ØD2
12	28,00	3,00
12	30,00	3,00
12	32,00	3,00
12	33,00	3,00
12	35,00	3,00
12	36,00	3,00
12	38,00	3,00
9	38,00	4,00
9	42,00	4,00
9	45,00	4,00

## DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Stock*	Price each 1 to 2
BOX-TOR-H	NBR 70 Sh A	404 o-rings	✓	27,73 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

## Our other products



PTA150

Articulated levelling foot, pressed base  
Ø150, Ø 150



DB

Steel bevel gear, 2:1




VRSSss

Male swivelling lifting rings stainless steel,  
Male swivelling - s...



PTA50

 Articulated levelling foot, pressed base  
Ø50, Ø 50



LWH

High rigidity linear slide, Chariot - from  
9320 N to 71300 N



PSG125

Spur gear - precision range, Case hardened  
steel 20NCD2



ES

Bipod support base,  
Plastic



PSG255

Spur gear - precision range, Stainless steel  
316



BSB

Ball screw bearing unit, Support



TBD

Manual leadscrew table with opposing  
threads, 2kg



CHM40-MOT

Asynchronous AC motorgearboxes 0.18 to  
0.55kW, 0.18 to



OPFL\_OPPM

Numerical counter accessories,  
Operating knob

## Complementary products



BOX-TOR-TOOL

Box set of tool for  
Nitrile O-rings,  
Extraction tools